

Special



Image for illustrative purpose only

## Summary

[Request a quote](#)

SE series

Number of contacts Low Voltage	1
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.20 - 3.20 mm
Size	1S
Suggested matching part	<a href="#">ERA.1S.120.CTL</a>
Series	S - Indoor Stepped Insert

[https://www.lemo.com/int\\_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	1
Contact Termination Low voltage	Solder
Insert configuration value	1S.120 - 1 Low Voltage
Insulator	T: PTFE
Rated current	18 A
Test voltage (kV DC)	2.7

## Form & Material

Shell style / Model id	FLA - Elbow plug, cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Gray
Weight	25.38 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr


[https://www.lemo.com/int\\_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.20 - 3.20 mm

## Drawings

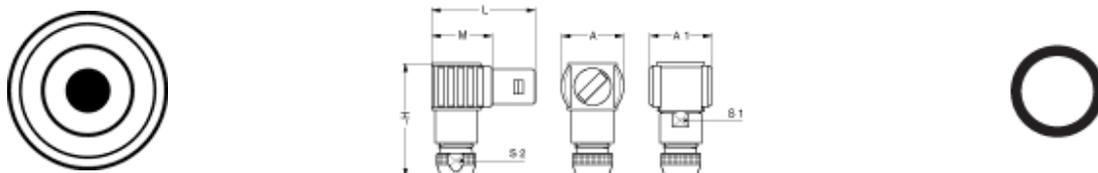

## Dimensions

	A	H	L	M	S1	S2	A1
mm.	16	28.5	26.5	15.5	10	8.5	16
in.	0.63	1.12	1.04	0.61	0.39	0.33	0.63

## Recommended By Lemo

### Accessories

Compatible cap [BFG.1B.100.PCZG](#)

## CAD

### Documents

Eplan [Download](#)

[https://www.lemo.com/int\\_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/507495/s/fla-1s-120-ctac27/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.