

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.90 - 6.50 mm
Size	1S
Suggested matching part	ERA.1S.275.CTL
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/catalog/product/view/id/425934/s/fla-1s-275-ctac66/category/38/

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Insert configuration value	1S.275 - 1 Coax (75 Ohm)
Insulator	T: PTFE
Rated current	10 A
Impedance	75 Ohms
VSWR	1.02 + 0.08 * f/GHz
Vtest	2400 V (AC), 3300 V (DC)
Cable type	10361
Bucket Dia.	1.1 mm (0.0432in)
Contact Dia.	1.3 mm (0.0512in)

Form & Material

Shell style / Model id	FLA - Elbow plug, cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Gray
Weight	24.06 g

https://www.lemo.com/int_en/catalog/product/view/id/425934/s/fla-1s-275-ctac66/category/38/

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.90 - 6.50 mm

Drawings

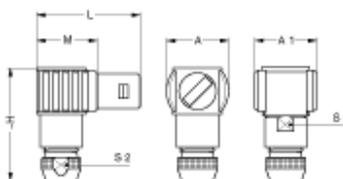

Dimensions

	A	H	L	M	S1	S2	A1
mm.	16	28.5	26.5	15.5	10	8.5	16
in.	0.63	1.12	1.04	0.61	0.39	0.33	0.63

https://www.lemo.com/int_en/catalog/product/view/id/425934/s/fla-1s-275-ctac66/category/38/

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Compatible cap

[BFG.1B.100.PCZG](#)

Cables

Cable PartNumber	Material	Colour	Cable image
159580	PVC	Black	
62000	PVC	Black	
CCX.50.RG0.58AU61J	PVC	Yellow	
CCX.75.RG0.59BU62N	PVC	Black	
CCX.93.RG0.62AU62N	PVC	Black	

https://www.lemo.com/int_en/catalog/product/view/id/425934/s/fla-1s-275-ctac66/category/38/

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.