

Standard



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

### BKT series

|                                    |                                |
|------------------------------------|--------------------------------|
| Number of contacts Low Voltage     | 7                              |
| Wire Size/AWG                      | 30 - 22                        |
| Gender                             | Standard                       |
| Plug                               | Plug - Elbow                   |
| Locking system                     | Push-pull                      |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm                 |
| Size                               | 1B                             |
| Suggested matching part            | <a href="#">EGG.1B.307.CLL</a> |
| Series                             | B - Indoor keyed               |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

|                                 |                               |
|---------------------------------|-------------------------------|
| Number of contacts Low Voltage  | 7                             |
| Contact Termination Low voltage | Solder                        |
| R (max)                         | 6.1 mOhm                      |
| Insert configuration value      | 1B.307 - 7 Low Voltage        |
| Insulator                       | L: PEEK (UL 94 / V-0/1.5)     |
| Rated current                   | 7 A                           |
| Vtest (contact-contact)         | 1.4 kV (DC)                   |
| Vtest (contact-shell)           | 1.5 kV (DC)                   |
| Max. Conductor                  | 0.34 mm <sup>2</sup> (AWG 22) |
| Max. Stranded Conductor         | 0.34 mm <sup>2</sup> (AWG 22) |
| Bucket Dia.                     | 0.8 mm (0.031in)              |
| Contact Dia.                    | 0.7 mm (0.028in)              |
| Wire Size/AWG                   | 30 - 22                       |
| Gender                          | Standard                      |

## Form & Material

|                        |                                                                                                                               |
|------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| Shell style / Model id | FS - Adjustable right angle Anglissimo plug (8 selective positions) with cable collet and nut for fitting a bend relief       |
| Plug                   | Elbow                                                                                                                         |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system         | Push-pull                                                                                                                     |
| Keying                 | G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)                                                          |
| Colour                 | Grey                                                                                                                          |
| Variant                | Nut for fitting a bend relief                                                                                                 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

|                                   |                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | IP50                                                                                                                                       |
| Endurance                         | 5000 mating cycles                                                                                                                         |
| Temperature range                 | -55°C / +250°C (max. temperature valid for short periods of use.)                                                                          |
| Climatic Category                 | 55/175/21                                                                                                                                  |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]                                                                                                                 |
| Shielding (min)                   | 75 dB (10 MHz)                                                                                                                             |
| Shielding (min)                   | 40 dB (1 GHz)                                                                                                                              |
| Shock Resistance                  | 100 g [ 6 ms]                                                                                                                              |
| Vibration                         | 15 g [10 Hz - 2000 Hz]                                                                                                                     |
| Salt Spray Corrosion              | >1000 hr                                                                                                                                   |
| Note                              | Cable diameter is specific for Anglissimo to enable easy termination of connector                                                          |

## Cable fixation

|                                    |                       |
|------------------------------------|-----------------------|
| Cable termination protection       | For cable bend relief |
| Fixation type                      | Cable collet          |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm        |

## Drawings

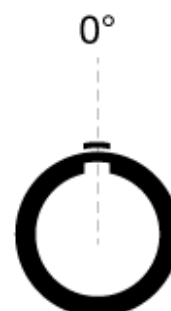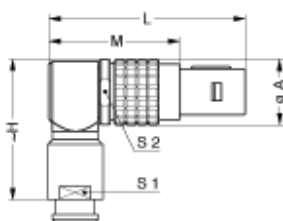

## Dimensions

|     | A    | L    | M    | S1   | S2   | H    |
|-----|------|------|------|------|------|------|
| mm. | 12   | 36.5 | 25.5 | 9    | 11   | 30.8 |
| in. | 0.47 | 1.44 | 1    | 0.35 | 0.43 | 1.21 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsg-1b-307-clad62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

| Accessories    |                                  |
|----------------|----------------------------------|
| Compatible cap | <a href="#">BFG.1B.100.PCZG</a>  |
| Tools          |                                  |
| Spanner        | <a href="#">DCP.0T.110.TN</a>    |
| Spanner 2      | <a href="#">DCP.91.FSG.TN</a>    |
| Spanner wrench | <a href="#">DCD.1B.ZZZ.PA090</a> |

## Cables

| Cable PartNumber | Material | Colour | Cable image                                                                         |
|------------------|----------|--------|-------------------------------------------------------------------------------------|
| 270250           | PVC      | Grey   |  |