

Standard*Image for illustrative purpose only*

Summary

[Request a quote](#)**SE series****Size**

0E

Series

E - Outdoor Stepped Insert

Technical details


Form & Material

Shell style / Model id	GCA - Earthing washer
Housing material	Brass (CuSnZn plated)
Keying	No keying
Weight	0.43 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	No IP rating
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

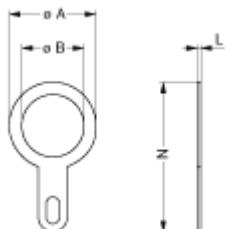

No keying

Dimensions

	A	B	L	N
mm.	17	14.1	0.5	27.5
in.	0.67	0.56	0.02	1.08

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/gca-0e-255-it.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.