



Image for illustrative purpose only

Summary

[Request a quote](#)

SE series

Size	0S
Series	S - Indoor Stepped Insert

Technical details


Form & Material

Shell style / Model id	GCA - Earthing washer
Housing material	Brass (CuSnZn plated)
Keying	No keying
Weight	0.31 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	No IP rating
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

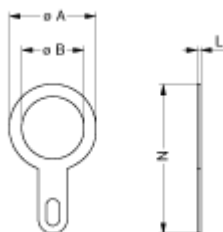

No keying

Dimensions

	A	B	L	N
mm.	13	9.1	0.4	22
in.	0.51	0.36	0.02	0.87

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/gca-0s-255-lt.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.