

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

| | |
|--------|------------------|
| Size | 0B |
| Series | B - Indoor keyed |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-025-sn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

| | |
|------------------------|--------------------------|
| Shell style / Model id | GMA - Bend relief Black |
| Housing material | Santoprene thermoplastic |
| Keying | No keying |
| Colour | Black |
| Weight | 0.32 g |

Environment

| | |
|-----------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating |
| Temperature range | -55°C / +250°C (max. temperature valid for short periods of use.) |
| Climatic Category | 55/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 75 dB (10 MHz) |
| Shielding (min) | 40 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |

Drawings

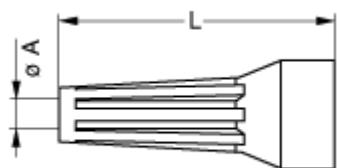

No keying

Dimensions

| | A | L |
|-----|-----|------|
| mm. | 2.5 | 24 |
| in. | 0.1 | 0.94 |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-025-sn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.