

Standard



Image for illustrative purpose only

## Summary

[Request a quote](#)

[BKT series](#)

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 4.00 - 4.40 mm   |
| Size                               | 0B               |
| Series                             | B - Indoor keyed |

# Technical details

## Form & Material

|                        |                            |
|------------------------|----------------------------|
| Shell style / Model id | GMA - Bend relief Grey     |
| Housing material       | Thermoplastic polyurethane |
| Keying                 | No keying                  |
| Colour                 | Grey                       |
| Weight                 | 0.46 g                     |


## Environment

|                                   |                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating                                                                                                                               |
| Temperature range                 | -40°C / +80°C                                                                                                                              |

## Cable fixation

|                                    |                |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 4.00 - 4.40 mm |
|------------------------------------|----------------|

# Drawings

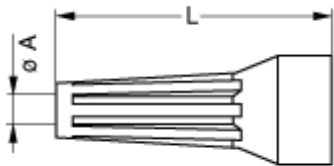

No keying

# Dimensions

|     | A    | L    |
|-----|------|------|
| mm. | 4.0  | 24   |
| in. | 0.16 | 0.94 |