

Standard



Image for illustrative purpose only

## Summary

[Request a quote](#)

[BKT series](#)

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 2.50 - 2.90 mm   |
| Size                               | 1B               |
| Series                             | B - Indoor keyed |

# Technical details

## Form & Material

|                        |                        |
|------------------------|------------------------|
| Shell style / Model id | GMA - Bend relief Grey |
| Housing material       | Silicone elastomer VMQ |
| Keying                 | No keying              |
| Colour                 | Grey                   |
| Weight                 | 0.95 g                 |


## Environment

|                                   |                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating                                                                                                                               |
| Temperature range                 | -60°C / +200°C (max. temperature valid for short periods of use.)                                                                          |
| Temperature range in water steam  | +140°C                                                                                                                                     |

## Cable fixation

|                                    |                |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 2.50 - 2.90 mm |
|------------------------------------|----------------|

# Drawings

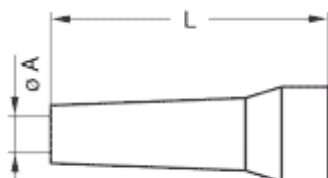

No keying

## Dimensions

|     | A   | L    |
|-----|-----|------|
| mm. | 2.5 | 34   |
| in. | 0.1 | 1.34 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-1b-025-rg.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-025-rg.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.