

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Jacket cable outside diameter [mm]	4.00 - 4.40 mm
Size	1B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	0.84 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

Cable fixation

Jacket cable outside diameter [mm]	4.00 - 4.40 mm
------------------------------------	----------------

Drawings

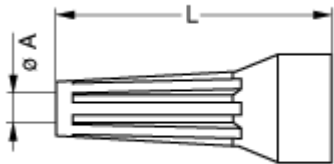

No keying

Dimensions

	A	L
mm.	4.0	30
in.	0.16	1.18