

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
Size	1B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Silicone elastomer VMQ
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	1.02 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-60°C / +200°C (max. temperature valid for short periods of use.)
Temperature range in water steam	+140°C

Cable fixation

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
------------------------------------	----------------

Drawings

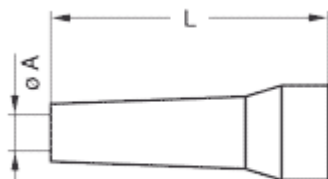

No keying

Dimensions

	A	L
mm.	4.5	34
in.	0.18	1.34

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-045-rj.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.