

Standard



Image for illustrative purpose only

## Summary

[Request a quote](#)

BKT series

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 5.40 - 6.00 mm   |
| Size                               | 1B               |
| Series                             | B - Indoor keyed |

# Technical details

## Form & Material

|                        |                            |
|------------------------|----------------------------|
| Shell style / Model id | GMA - Bend relief Yellow   |
| Housing material       | Thermoplastic polyurethane |
| Keying                 | No keying                  |
| Colour                 | Yellow                     |
| Variant                | Yellow                     |
| Weight                 | 0.94 g                     |


## Environment

|                                   |                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating                                                                                                                               |
| Temperature range                 | -40°C / +80°C                                                                                                                              |

## Cable fixation

|                                    |                |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 5.40 - 6.00 mm |
|------------------------------------|----------------|

# Drawings

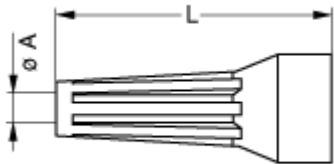

No keying

## Dimensions

|     | A    | L    |
|-----|------|------|
| mm. | 5.4  | 30   |
| in. | 0.21 | 1.18 |