

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Size	2B
Series	B - Indoor keyed

Technical details


Form & Material

Shell style / Model id	GMA - Bend relief Black
Housing material	Santoprene thermoplastic
Keying	No keying
Colour	Black
Weight	1.8 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

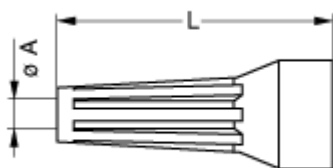

No keying

Dimensions

	A	L
mm.	7.0	36
in.	0.28	1.42

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-2b-070-sn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.