

Standard



Image for illustrative purpose only

## Summary

[Request a quote](#)

[BKT series](#)

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 7.80 - 8.80 mm   |
| Size                               | 2B               |
| Series                             | B - Indoor keyed |

# Technical details

## Form & Material

|                        |                            |
|------------------------|----------------------------|
| Shell style / Model id | GMA - Bend relief White    |
| Housing material       | Thermoplastic polyurethane |
| Keying                 | No keying                  |
| Colour                 | White                      |
| Variant                | White                      |
| Weight                 | 1.88 g                     |


## Environment

|                                   |                                                                                                                                            |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating                                                                                                                               |
| Temperature range                 | -40°C / +80°C                                                                                                                              |

## Cable fixation

|                                    |                |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 7.80 - 8.80 mm |
|------------------------------------|----------------|

# Drawings

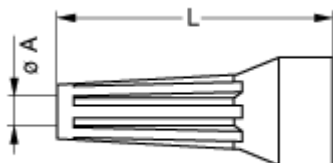

No keying

## Dimensions

|     | A    | L    |
|-----|------|------|
| mm. | 7.8  | 36   |
| in. | 0.31 | 1.42 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-2b-080-db.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-2b-080-db.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.