

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Jacket cable outside diameter [mm]	7.80 - 8.80 mm
Size	2B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	1.8 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

Cable fixation

Jacket cable outside diameter [mm]	7.80 - 8.80 mm
------------------------------------	----------------

Drawings

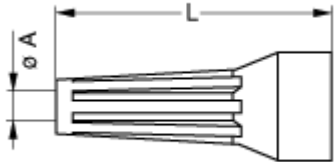

No keying

Dimensions

	A	L
mm.	7.8	36
in.	0.31	1.42