

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Jacket cable outside diameter [mm]	8.00 - 9.00 mm
Size	2B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Red
Housing material	Silicone elastomer VMQ
Keying	No keying
Colour	Red
Weight	1.6 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-60°C / +200°C (max. temperature valid for short periods of use.)
Temperature range in water steam	+140°C

Cable fixation

Jacket cable outside diameter [mm]	8.00 - 9.00 mm
------------------------------------	----------------

Drawings

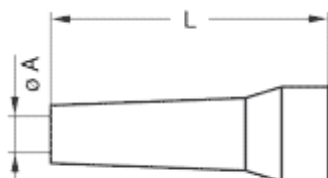

No keying

Dimensions

	A	L
mm.	8.0	41
in.	0.31	1.61

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-2b-080-rr.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.