

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Jacket cable outside diameter [mm]	6.00 - 6.90 mm
Size	3B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief White
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	White
Variant	White
Weight	2.27 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

Cable fixation

Jacket cable outside diameter [mm]	6.00 - 6.90 mm
------------------------------------	----------------

Drawings

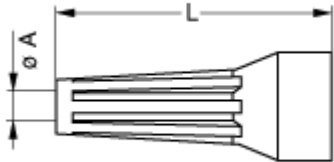

No keying

Dimensions

	A	L
mm.	6.0	42
in.	0.24	1.65