

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Jacket cable outside diameter [mm]	9.00 - 10.00 mm
Size	3B
Series	B - Indoor keyed

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	2.96 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

Cable fixation

Jacket cable outside diameter [mm]	9.00 - 10.00 mm
------------------------------------	-----------------

Drawings

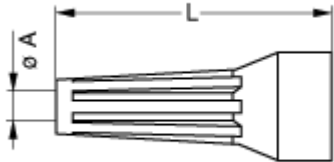

No keying

Dimensions

	A	L
mm.	9.0	42
in.	0.35	1.65