

Special



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

BKT series

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 11.00 - 11.90 mm |
| Size                               | 4B               |
| Series                             | B - Indoor keyed |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-4b-011-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-4b-011-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Form & Material

|                        |                            |
|------------------------|----------------------------|
| Shell style / Model id | GMA - Bend relief Yellow   |
| Housing material       | Thermoplastic polyurethane |
| Keying                 | No keying                  |
| Colour                 | Yellow                     |
| Variant                | Yellow                     |
| Weight                 | 5.89 g                     |


## Environment

|                                   |  |
|-----------------------------------|--|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating   |
| Temperature range                 | -40°C / +80°C  |

## Cable fixation

|                                    |                  |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 11.00 - 11.90 mm |
|------------------------------------|------------------|

# Drawings

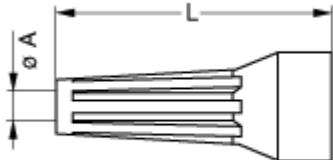

No keying

## Dimensions

|     | A    | L    |
|-----|------|------|
| mm. | 11.0 | 60   |
| in. | 0.43 | 2.36 |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-4b-011-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-4b-011-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.