

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Jacket cable outside diameter [mm]	13.50 - 14.50 mm
Size	4B
Series	B - Indoor keyed

Technical details

Electrical Configuration

Footprint IPC Class3 compatibility	No
------------------------------------	----

Form & Material

Shell style / Model id	GMA - Bend relief Blue
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	Blue
Weight	6.58 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

Cable fixation

Jacket cable outside diameter [mm]	13.50 - 14.50 mm
------------------------------------	------------------

Drawings

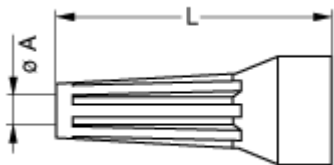

No keying

Dimensions

	A	L
mm.	13.5	60
in.	0.53	2.36