

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[unipole multipole](#)

Jacket cable outside diameter [mm]	2.50 - 2.80 mm
Size	00

Technical details

Form & Material

Shell style / Model id	GMD - Bend relief White
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	White
Variant	White
Weight	0.28 g


Environment

Environmental sealing (IP rating)	No IP rating
-----------------------------------	--------------

Cable fixation

Jacket cable outside diameter [mm]	2.50 - 2.80 mm
------------------------------------	----------------

Drawings

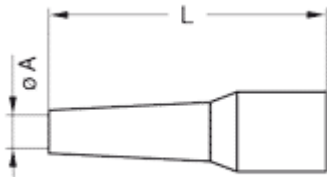

No keying

Dimensions

	A	L
mm.	2.5	22
in.	0.1	0.87

https://www.lemo.com/int_en/gmd-00-025-db.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.