

**GRA.00.269.GB**



Standard



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[unipole multipole](#)

Size	00
------	----

[https://www.lemo.com/int\\_en/gra-00-269-gb.html](https://www.lemo.com/int_en/gra-00-269-gb.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	GRA - Insulating washer
Housing material	Polyamide, white
Keying	No keying
Weight	0.05 g

## Environment

Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +90°C

## Drawings

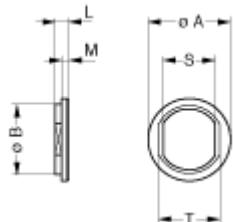

No keying

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>M</b>	<b>S</b>	<b>T</b>
mm.	10	8.8	1.8	1	6.4	8
in.	0.39	0.35	0.07	0.04	0.25	0.31

[https://www.lemo.com/int\\_en/gra-00-269-gb.html](https://www.lemo.com/int_en/gra-00-269-gb.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.