

Special



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

SE series

|        |                           |
|--------|---------------------------|
| Size   | 4S                        |
| Series | S - Indoor Stepped Insert |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/gra-4s-269-gj.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/gra-4s-269-gj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

|                        |                         |
|------------------------|-------------------------|
| Shell style / Model id | GRA - Insulating washer |
| Housing material       | Polyamide, yellow       |
| Keying                 | No keying               |
| Weight                 | 0.7 g                   |

## Environment

|                                   |                                                                         |
|-----------------------------------|-------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental sealing (IP rating) | No IP rating                                                            |
| Temperature range                 | -40°C / +90°C                                                           |
| Climatic Category                 | 55/175/21                                                               |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]                                              |
| Shielding (min)                   | 75 dB (10 MHz)                                                          |
| Shielding (min)                   | 40 dB (1 GHz)                                                           |
| Shock Resistance                  | 100 g [ 6 ms]                                                           |
| Vibration                         | 15 g [10 Hz - 2000 Hz]                                                  |

## Drawings

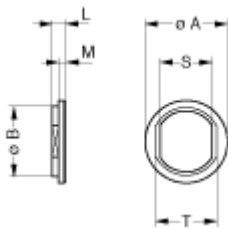

No keying

## Dimensions

|     | A    | B    | L   | M    | S    | T    |
|-----|------|------|-----|------|------|------|
| mm. | 31.9 | 28.7 | 2.5 | 1.5  | 23.6 | 27.1 |
| in. | 1.26 | 1.13 | 0.1 | 0.06 | 0.93 | 1.07 |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/gra-4s-269-gj.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/gra-4s-269-gj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.