

[Standard](#)

Image for illustrative purpose only

Summary

[Request a quote](#)[P series catalog](#)[Industry Brochure Medical](#)

Number of contacts High Voltage	3
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.00 - 5.20 mm
Size	1P
Suggested matching part	PKH.N0.3GL.AG
Series	REDEL P - Push-Pull

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/pah-n0-3gl-lc52gz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts High Voltage	3
Contact Termination High voltage	Solder
R (max) - electrical contact resistance	4.5 mOhm
Insert configuration value	1P.N03 - 3 High Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	9 A
Test voltage contact-contact	4.81 (kV DC)
Max. Solid Conductor	1 mm ² (AWG 18)
Max. Stranded Conductor	1 mm ² (AWG 18)
Air clearance	2.00 mm
Creepage distance	2.00 mm
Cable type	H07 RN-F
Bucket Dia.	1.4 mm (0.055 in)
Contact Dia.	0.9 mm (0.035 in)
Gender	Reverse Gender

Form & Material

Shell style / Model id	PA - Straight plug with cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	PSU (Polysulfone), grey
Locking system	Push-pull
Keying	H: 2 keys (beta=170, plug: female contacts, receptacle: male contacts)
Colour	Grey
Variant	Grey collet nut for bend relief
Weight	5.41 g

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/pah-n0-3gl-lc52gz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	> 5000 mating cycles
Temperature range	-50°C / +150°C
F ret (max)	150 N
F ret (min)	50 N
Steam sterilization	Compiles with ISO 17665:2024 sterilization standard for autoclave, ISO 11135:2014 for EtO, and ISO 11137-1, -2, -3 standards for gamma, e-beam x-ray. For more details on sterilization methods and cycles, please contact us.

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.00 - 5.20 mm

Drawings

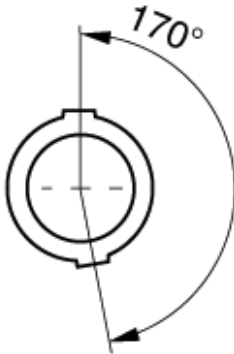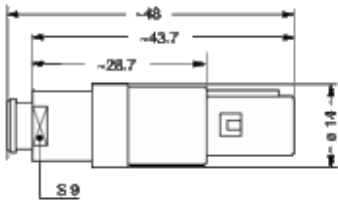

Recommended By Lemo

Bend Reliefs		
GMA.1B.040.RG	GMA.1B.045.RG	GMA.1B.040.RA
GMA.1B.045.RA	GMA.1B.040.RB	GMA.1B.045.RB
GMA.1B.040.RJ	GMA.1B.045.RJ	GMA.1B.040.RM
GMA.1B.045.RM	GMA.1B.040.RN	GMA.1B.045.RN
GMA.1B.040.RR	GMA.1B.045.RR	GMA.1B.040.RS
GMA.1B.045.RS	GMA.1B.040.RV	GMA.1B.045.RV