

Special

*Image for illustrative purpose only*

## Summary

[Request a quote](#)[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	26 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Ratchet
Jacket cable outside diameter [mm]	4.00 - 8.00 mm
Size	0M
Suggested matching part	<a href="#">FMN.0M.304.ILC</a>
Series	M - Rugged Ratchet coupling

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	0M.304 - 4 Low Voltage
Insulator	L: PEEK
Rated current	7 A
Test voltage (kV rms) Contact-contact	1.35
Test voltage (kV rms) Contact-shell	0.9
Contact retention	22 N
Max. Conductor	0.34 mm <sup>2</sup> (AWG 22)
Min. Conductor	0.14 mm <sup>2</sup> (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	26 - 22
Gender	Standard

## Form & Material

Shell style / Model id	PE - Fixed receptacle, nut fixing and mold stop
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Aluminium (NiCorAl Nickel fluorocarbon polymer, anthracite color) shell and nut, other pieces bronze/brass
Locking system	Ratchet
Keying	3 keys (beta=165, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	7.58 g

[https://www.lemo.com/int\\_en/catalog/product/view/id/587457/s/pen-0m-304-ilmt/category/56/](https://www.lemo.com/int_en/catalog/product/view/id/587457/s/pen-0m-304-ilmt/category/56/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

Technical domain	Motorsport, Security and Defence, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP68
Endurance	3000 mating cycles
Temperature range	-20°C / +200°C (max. temperature valid for short periods of use.)
EMI Shielding EIA 364-66A	>= 80 dB (1 GHz), >=70 dB (3 GHz), >= 58 dB (6 GHz), >= 40 dB (10 GHz)
Gunfire vibration	25 Hz - 2000 Hz, 3 axis (Apache helicopter)
Humidity (max)	21 days at 95%
Lighting strike EIA 364-76	10K amps - 6 times
Shock Resistance	300 g [ 3 ms]
Thermal shock	5 cycles: -65°C to +150°C
Vibration-Random	37.8 g rms - 3 axes, 4 hr amb [50 Hz - 2000 Hz]
Vibration-Sine	30 g, 3 axes, 12 hr [10 Hz - 2000 Hz]
Salt Spray Corrosion	max. 500 hr

## Cable fixation

Cable termination protection	For overmolding
Fixation type	Mold stop (overmolding)
Jacket cable outside diameter [mm]	4.00 - 8.00 mm

## Drawings

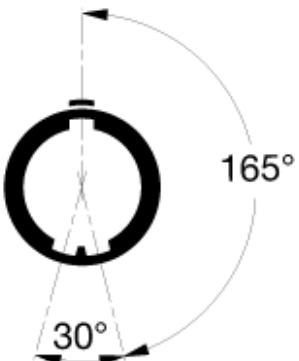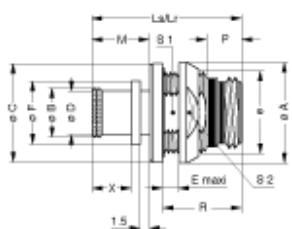

## Dimensions

	<b>A</b>	<b>B</b>	<b>C</b>	<b>D</b>	<b>E</b>	<b>e</b>	<b>Ls</b>	<b>Lr</b>	<b>M</b>	<b>P</b>	<b>R</b>	<b>S1</b>	<b>S2</b>
mm.	17	8.8	16.8	8	5	M13x0.75	25.6	25.6	9.7	5.3	13.8	11.5	14
in.	0.67	0.35	0.66	0.31	0.2		1.01	1.01	0.38	0.21	0.54	0.45	0.55

## Recommended By Lemo

### Accessories

Replacement contact	EGN.0M.655.ZZM
---------------------	----------------

### Tools

Spanner 2	DCM.65.140.AZ
Positionner	DCE.91.070.3MVM
Extraction tool	DCC.07.04B.LAG
Crimp tool	DPC.91.701.V
Spanner wrench	DCM.65.140.AZ

[https://www.lemo.com/int\\_en/catalog/product/view/id/587457/s/pen-0m-304-ilmt/category/56/](https://www.lemo.com/int_en/catalog/product/view/id/587457/s/pen-0m-304-ilmt/category/56/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.