

Standard*Image for illustrative purpose only*

Summary

[Request a quote](#)**BKT series**

Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.60 - 8.00 mm
Size	2T
Suggested matching part	FGG.2T.316.CLAC80
Series	T - Small Outdoor keyed

Technical details

Electrical Configuration

R (max)	6.1 mOhm
Rated current	6 A
Vtest (contact-contact)	1.4 kV (DC)
Vtest (contact-shell)	1.8 kV (DC)
Max. Solid Conductor	0.34 mm ² (AWG 22)
Max. Stranded Conductor	0.34 mm ² (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	PH - Free receptacle, cable collet and nut for fitting a bend relief
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	31.46 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr



https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phg-2t-316-cllc80z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.60 - 8.00 mm

Drawings

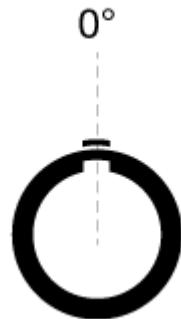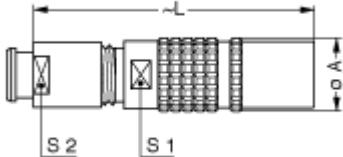

Dimensions

	A	L	S1	S2
mm.	15	51	13	12
in.	0.59	2.01	0.51	0.47

Recommended By Lemo

Accessories

Compatible cap	BRF.2T.200.CAZ
----------------	----------------

Tools

Spanner	DCP.2T.110.TN
---------	---------------

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.16.T22.076QGZE	TPR (medical)	Grey	A photograph of a grey cylindrical cable. Several thin, multi-colored wires are visible, fanned out at the end of the cable. The wires are color-coded in various shades of red, blue, green, and yellow.

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/phg-2t-316-cllc80z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.