



Image for illustrative purpose only

Summary

[Request a quote](#)

[r series](#)

Number of contacts Low Voltage	13
Wire Size/AWG	32 - 28
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	1.00 - 4.00 mm
Size	RR
Suggested matching part	FGG.RR.313.ALC40

https://www.lemo.com/int_en/phg-rr-313-alm40.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	13
Contact Termination Low voltage	Crimp
Insert configuration value	RR.313 - 13 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	0,5 A
Test voltage (kV rms) Contact-contact	0.6
Contact Dia.	0.5 mm (0.0197 in)
Wire Size/AWG	32 - 28

Form & Material

Shell style / Model id	PHG - Free receptacle, cable collet key (G) or key (A), with cable collet
Socket / Receptacle	Free
Housing material	Crastin® PBT (Polybutylene terephthalate), blue
Locking system	Push-pull
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Weight	2.7 g

Environment

Environmental sealing (IP rating)	IP50
Temperature range	-30°C / +150° C



Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	1.00 - 4.00 mm

Drawings

https://www.lemo.com/int_en/phg-rr-313-alm40.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

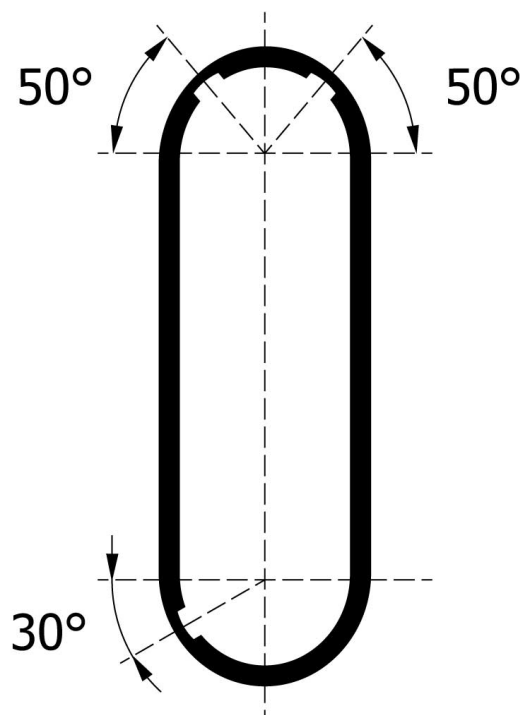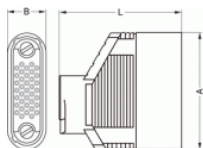

Dimensions

	A	B	L
mm.	18	6	22.3
in.	0.71	0.24	0.88

Recommended By Lemo

Contacts

Replacement contact [EGG.00.654.ZZM](#)

Tools

Positionner [DCE.91.050.0VM](#)

Extraction tool [DCC.05.02B.LAG](#)

Crimp tool [DPC.91.701.V](#)

https://www.lemo.com/int_en/phg-rr-313-alm40.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.