

*Image for illustrative purpose only*

Summary

[Request a quote](#)[P series catalog](#)

Gender	Standard
Locking system	Push-pull
Size	1P
Series	REDEL P - Push-Pull

Technical details

Electrical Configuration

Footprint IPC Class3 compatibility	No
Gender	Standard

Form & Material

Shell style / Model id	POB - Spanner for front nut
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	3.05 g


Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +150°C
Steam sterilization	Compiles with ISO 17665:2024 sterilization standard for autoclave, ISO 11135:2014 for EtO, and ISO 11137-1, -2, -3 standards for gamma, e-beam x-ray. For more details on sterilization methods and cycles, please contact us.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--

Drawings

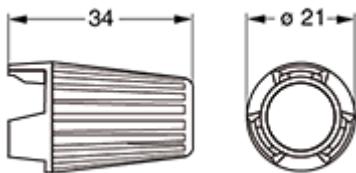

https://www.lemo.com/int_en/solutions/redele/redele-p-push-pull/pob-186-gn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.