



Image for illustrative purpose only

Summary

[Request a quote](#)

[Coax triax mixed en](#)

Nb of contacts Coax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.10 - 3.50 mm
Size	0E
Suggested matching part	FFA.0E.250.CTAC35
Series	E - Outdoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-250-ctlc35.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Insert configuration value	0E.250 - 1 Coax (50 Ohm)
Footprint IPC Class3 compatibility	No
Insulator	T: PTFE
Rated current	6 A
Impedance	50 Ohms
VSWR	$1.02 + 0.25 * f/\text{GHz}$
Vtest	3000 V (AC), 4200 V (DC)
Cable type	RG 178 B/U, RG 196 A/U, RG 188 A/U, RG 316 B/U, RG 174 A/U, HF-2114, RG 122 /U
Bucket Dia.	1 mm (0.039in)
Contact Dia.	0.9 mm (0.035in)

Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Circular, female
Colour	Grey
Weight	20.6 g

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-250-ctlc35.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.10 - 3.50 mm
Panel Drill Hole	M14

Drawings

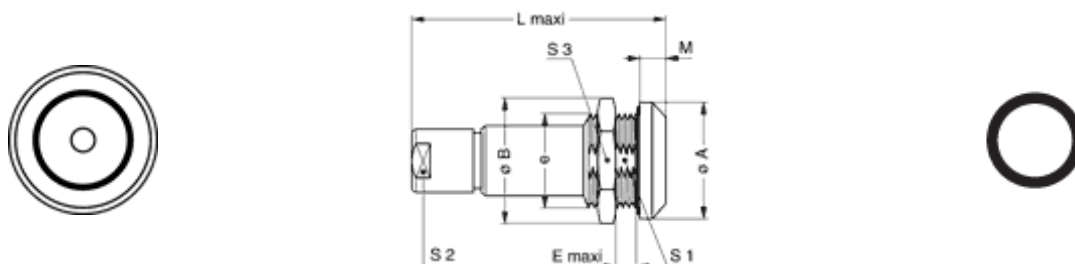

Dimensions

	A	B	e	E	L	M	S1	S2	S3
mm.	18	19.5	M14x1.0	5.5	34	4	12.5	8	17
in.	0.71	0.77		0.22	1.34	0.16	0.49	0.31	0.67

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-250-ctlc35.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Compatible cap	BRE.0K.200.NAS

Cables

Cable PartNumber	Material	Colour	Cable image
CCX.75.040.195327G	PVC	Grey	