

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[Coax triax mixed en](#)

Nb of contacts Coax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M15
Jacket cable outside diameter [mm]	4.30 - 5.20 mm
Size	2S
Suggested matching part	FFA.2S.250.CTAC52
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-2s-250-ctlc52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Insert configuration value	2S.250 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	15 A
Impedance	50 Ohms
VSWR	1.02 + 0.95 * f/GHz
Vtest	3000 V (AC), 4200 V (DC)
Cable type	RG 58 C/U, RG 302 /U, RG 400 /U, 2YCCY, RG 59 B/U, RG 223 /U, HF-5408
Bucket Dia.	1.8 mm (0.071in)
Contact Dia.	2 mm (0.079in)

Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Colour	Grey
Weight	31.5 g
Panel Drill Hole	M15

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-2s-250-ctlc52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.30 - 5.20 mm

Drawings

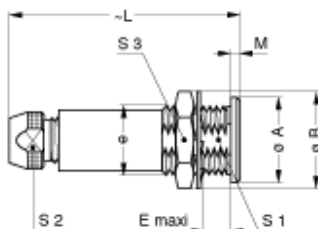

Dimensions

	A	B	e	E	L	M	S1	S2	S3	C
mm.	18	19.5	M15x1.0	8.5	50	1.8	13.5	11	17	8.5
in.	0.71	0.77		0.33	1.97	0.07	0.53	0.43	0.67	0.33

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-2s-250-ctlc52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Caps	
Compatible cap	BRE.2S.200.NAS
Cap 2	BRE.2S.200.NAV
Plastic Cap	BRA.2B.200.PCSG
Cap BRR	BRR.2S.200.PZVG
Soft Cap	BEZ.2B.200.SCN

Cables

Cable PartNumber	Material	Colour	Cable image
158480	PUR	Black	
158490	PVC	Black	
CCX.50.088.292495N	PVC	Black	
CCX.50.RG5.8CU50N	PVC	Black	