

[Standard](#)

Image for illustrative purpose only

Summary

[Request a quote](#)[REDEL SP series en](#)[Industry Brochure Medical](#)

Number of contacts Low Voltage	8
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Panel Drill Hole	M14
Jacket cable outside diameter [mm]	1.00 - 12.60 mm
Size	SP
Suggested matching part	SAN.M08.BLA.6BZ
Series	REDEL SP - Inner Push-Pull

Technical details

Electrical Configuration

Number of contacts Low Voltage	8
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	4.5 mOhm
Insert configuration value	SP.M08 - 8 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5 A
Test voltage contact-contact	2.1 (kV DC)
Max. Solid Conductor	0.34 mm ² (AWG 22)
Max. Stranded Conductor	0.34 mm ² (AWG 22)
Air clearance	0.75 mm
Creepage distance	0.75 mm
Bucket Dia.	0.8 mm (0.031 in)
Contact Dia.	0.9 mm (0.035 in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	SK_SP - Fixed socket, key (N) or keys (P, S and T), with two nuts (back panel mounting), white front nut
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Proprietary sulfone, white
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	White
Variant	White front nut
Weight	4.21 g
Panel Drill Hole	M14



Environment

Technical domain	Medical
Environmental sealing (IP rating)	IP50
Endurance	>5000 mating cycles
Temperature range	-50°C / +170°C
Steam sterilization	> 100 times

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	1.00 - 12.60 mm

Drawings

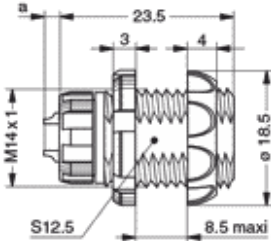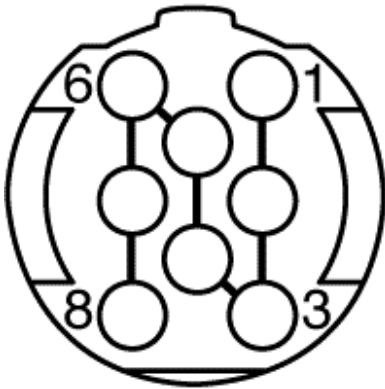

Dimensions

	a	B	N	e	Emax
mm.	2.2	18.5	23.5	M14x1	8.5
in.	0.09	0.73	0.93		0.33

 
Recommended By Lemo

Caps

Compatible cap	SBZ.200.SN
----------------	----------------------------

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.08.T22.059QGC	TPR	Grey	
CMN.08.T22.059QGZE	TPR (medical)	Grey	
CMN.08.T26.042QGZE	TPR (medical)	Grey	
108220	PVC	Black	
108240	PTFE	White	
108260	PTFE	White	
16080	PVC	Grey	
180240	PVC	Black	
180260	PVC	Black	
280250	PVC	Grey	
335990	PVC	Black	
335991	PVC	Black	
42265	PVC	Yellow	
80140	PVC	Grey	
8050	PVC	Black	
8280	PVC	Black	