

[Standard](#)

Image for illustrative purpose only

Summary

[Request a quote](#)[REDEL SP series en](#)[Industry Brochure Medical](#)

Number of contacts Low Voltage	13
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Panel Drill Hole	M14
Jacket cable outside diameter [mm]	1.00 - 12.60 mm
Size	SP
Suggested matching part	SAN.M13.GLA.6B SAN.M13.GLA.7B
Series	REDEL SP - Inner Push-Pull

Technical details

Electrical Configuration

Number of contacts Low Voltage	13
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	6.5 mOhm
Insert configuration value	SP.M13 - 13 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	4 A
Test voltage contact-contact	1.5 (kV DC)
Max. Solid Conductor	0.34 mm ² (AWG 22)
Max. Stranded Conductor	0.34 mm ² (AWG 22)
Air clearance	0.5 mm
Creepage distance	0.5 mm
Bucket Dia.	0.8 mm (0.031 in)
Contact Dia.	0.7 mm (0.028 in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	SK_SP - Fixed socket, key (N) or keys (P, S and T), with two nuts (back panel mounting), white front nut
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Proprietary sulfone, grey
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey - White
Variant	White front nut
Weight	4.45 g
Panel Drill Hole	M14


Environment

Technical domain	Medical
Environmental sealing (IP rating)	IP50
Endurance	>5000 mating cycles
Temperature range	-50°C / +170°C
Steam sterilization	> 100 times

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	1.00 - 12.60 mm

Drawings

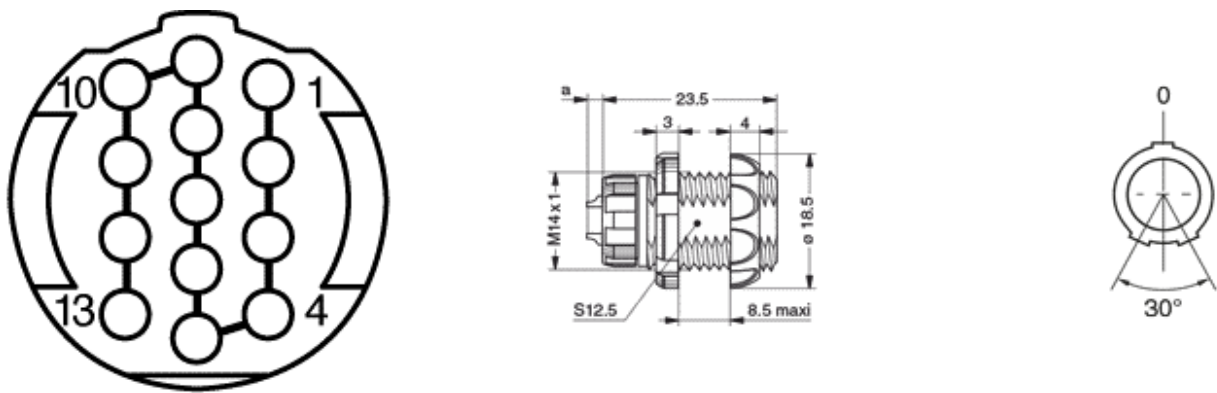

Dimensions

	a	B	N	e	E _{max}
mm.	2.2	18.5	23.5	M14x1	8.5
in.	0.09	0.73	0.93		0.33

Recommended By Lemo

Caps

Compatible cap	SBZ.200.SN
----------------	----------------------------

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.13.T22.072QGZE	TPR (medical)	Grey	