

Standard

*Image for illustrative purpose only*

Summary

[Request a quote](#)[Application leaflet Medical IEC 60601 1](#)[Industry Brochure Medical](#)

Number of contacts Low Voltage	22
Wire Size/AWG	34 - 28
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	1.00 - 12.60 mm
Size	SP
Suggested matching part	SAN.M22.GLA.6G
Series	REDEL SP - Inner Push-Pull

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/skn-m22-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	22
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	8.5 mOhm
Insert configuration value	SP.M22 - 22 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	2 A
Test voltage contact-contact	0.9 (kV DC)
Max. Solid Conductor	0.09 mm ² (AWG 28)
Max. Stranded Conductor	0.09 mm ² (AWG 28)
Air clearance	0.48 mm
Creepage distance	0.48 mm
Bucket Dia.	0.45 mm (0.018 in)
Contact Dia.	0.5 mm (0.0197 in)
Wire Size/AWG	34 - 28
Gender	Standard

Form & Material


Shell style / Model id	SK_SP - Fixed socket, key (N) or keys (P, S and T), with two nuts (back panel mounting), grey front nut
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Proprietary sulfone, grey
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Grey front nut
Weight	5.9 g

https://www.lemo.com/int_en/solutions/redel/redel-sp-inner-push-pull/skn-m22-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical domain	Medical
Environmental sealing (IP rating)	IP50
Endurance	>5000 mating cycles
Temperature range	-50°C / +170°C
Steam sterilization	> 100 times

Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	1.00 - 12.60 mm

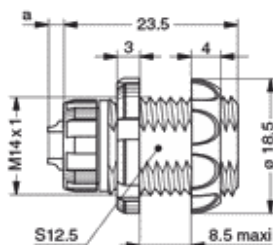

	a	B	N	e	E_{max}
mm.	2.2	18.5	23.5	M14x1	8.5
in.	0.09	0.73	0.93		0.33

Caps

Compatible cap	SBZ.200.SN
----------------	------------

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.22.T30.054QGZE	TPR (medical)	Grey	