

Special

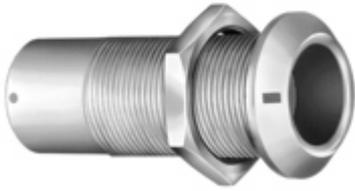


Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

| | |
|--------------------------------|-------------------|
| Number of contacts Low Voltage | 24 |
| Gender | Standard |
| Locking system | Push-pull |
| Panel Drill Hole | M24 |
| Size | 3K |
| Series | K - Outdoor keyed |

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-3k-324-clap.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

| | |
|--------------------------------|---------------------------|
| Number of contacts Low Voltage | 24 |
| Insert configuration value | 3K.324 - 24 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 4 A |
| Vtest (contact-contact) | 1.4 kV (DC) |
| Vtest (contact-shell) | 1.1 kV (DC) |
| Contact Dia. | 0.7 mm (0.03in) |
| Gender | Standard |

Form & Material

| | |
|------------------------|--|
| Shell style / Model id | SLG - Fixed coupler, nut fixing, key (G) or keys (L) at the flange end, and key (G) or keys (C or L) at the other end, watertight or vacuumtight |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces |
| Locking system | Push-pull |
| Keying | Front side: 2 key (gamma=75, male) , Other side: 1 key (alpha=0, female) |
| Colour | Grey |
| Variant | Watertight unmated (connector to device) |
| Weight | 146.45 g |
| Panel Drill Hole | M24 |


https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-3k-324-clap.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

| | |
|-----------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68 |
| Endurance | 5000 mating cycles |
| Temperature range | -20°C / +80°C |
| Climatic Category | 20/80/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 95 dB (10 MHz) |
| Shielding (min) | 80 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Pressure | 30 bars |
| Salt Spray Corrosion | >1000 hr |

Drawings

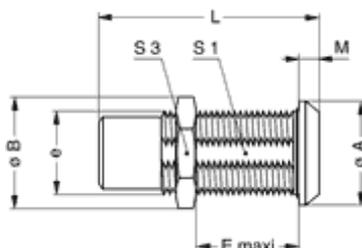

Dimensions

| | A | B | e | E | L | M | S1 | S3 |
|-----|------|------|---------|-----|------|------|------|------|
| mm. | 31 | 34 | M24x1.0 | 33 | 64 | 6 | 22.5 | 30 |
| in. | 1.22 | 1.34 | | 1.3 | 2.52 | 0.24 | 0.89 | 1.18 |

Recommended By Lemo

Accessories

Compatible cap

[BRE.3K.200.NAS](#)

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/slg-3k-324-clap.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.