

[Standard](#)

Image for illustrative purpose only

Summary

[Request a quote](#)[REDEL SP series en](#)[Industry Brochure Medical](#)

Number of contacts Low Voltage	13
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M14
Jacket cable outside diameter [mm]	1.00 - 12.60 mm
Size	SP
Suggested matching part	SAN.M13.BLA.6B SAN.M13.BLA.7BZ
Series	REDEL SP - Inner Push-Pull

Technical details

Electrical Configuration


Number of contacts Low Voltage	13
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	6.5 mOhm
Insert configuration value	SP.M13 - 13 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	4 A
Test voltage contact-contact	1.5 (kV DC)
Max. Solid Conductor	0.34 mm ² (AWG 22)
Max. Stranded Conductor	0.34 mm ² (AWG 22)
Air clearance	0.5 mm
Creepage distance	0.5 mm
Bucket Dia.	0.8 mm (0.031 in)
Contact Dia.	0.7 mm (0.028 in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	SL_SP - Fixed socket, key (N) or keys (P, S and T), nut fixing, white front nut
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Proprietary sulfone, white
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	White
Variant	White front nut
Weight	4.64 g
Panel Drill Hole	M14

Environment	
Technical domain	Medical
Environmental sealing (IP rating)	IP50
Endurance	>5000 mating cycles
Temperature range	-50°C / +170°C
Steam sterilization	> 100 times
Cable fixation	
Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	1.00 - 12.60 mm

Drawings

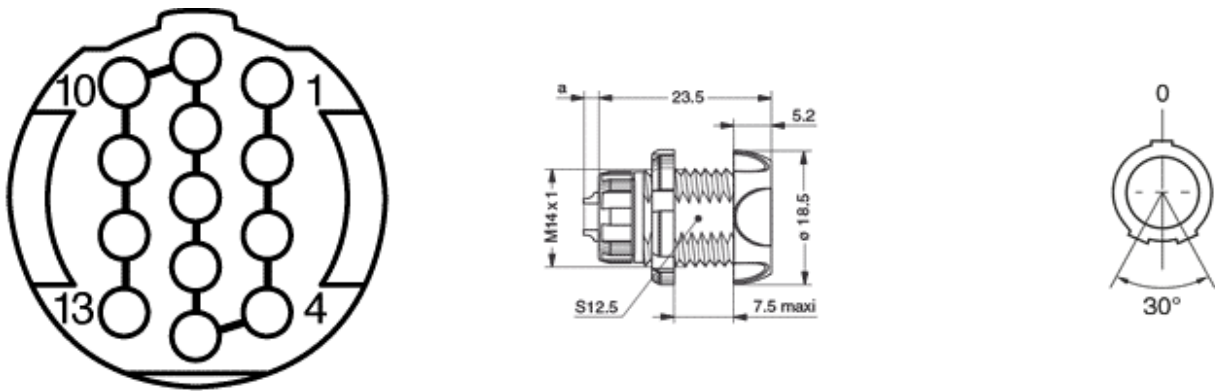

Dimensions

	a	B	N	e
mm.	2.2	18.5	23.5	M14x1
in.	0.09	0.73	0.93	

Recommended By Lemo

Caps	
Compatible cap	SBZ.200.SN

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.13.T22.072QGZE	TPR (medical)	Grey	