

Special*Image for illustrative purpose only*

Summary

[Request a quote](#)[SE series](#)

Number of contacts Low Voltage	22
Locking system	Push-pull
Panel Drill Hole	M25
Size	4S
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/swh-4s-322-cllpv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	22
Insert configuration value	4S.322 - 22 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 A
Test voltage (kV DC)	3
Contact Dia.	0.9 mm (0.035 in)

Form & Material

Shell style / Model id	SWH - Fixed coupler, nut fixing, watertight or vacuum-tight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying, pin 1 female on flange side, male on other side
Colour	Grey
Variant	Watertight / Vacuum-tested unmated (connector to device)
Weight	148.31 g
Panel Drill Hole	M25


https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/swh-4s-322-cllpv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	Hermetic unmated
Endurance	5000 mating cycles
Temperature range	-20°C / +80°C
Climatic Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Pressure	15 bars
R leak (He) (max)	10 ⁻⁷ mbar·l/s (if vacuum-tested)
Salt Spray Corrosion	>1000 hr

Drawings

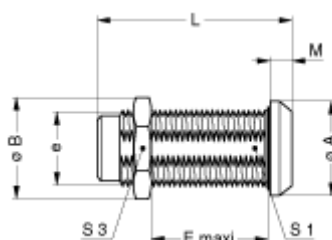

Dimensions

	A	B	e	E	L	M	S1	S3
mm.	34	32	M25x1.0	50	65	4	23.5	30
in.	1.34	1.26		1.97	2.56	0.16	0.93	1.18

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/swh-4s-322-cllpv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Caps	
Compatible cap	BRE.4S.200.NAS
Cap 2	BRE.4S.200.NAV