


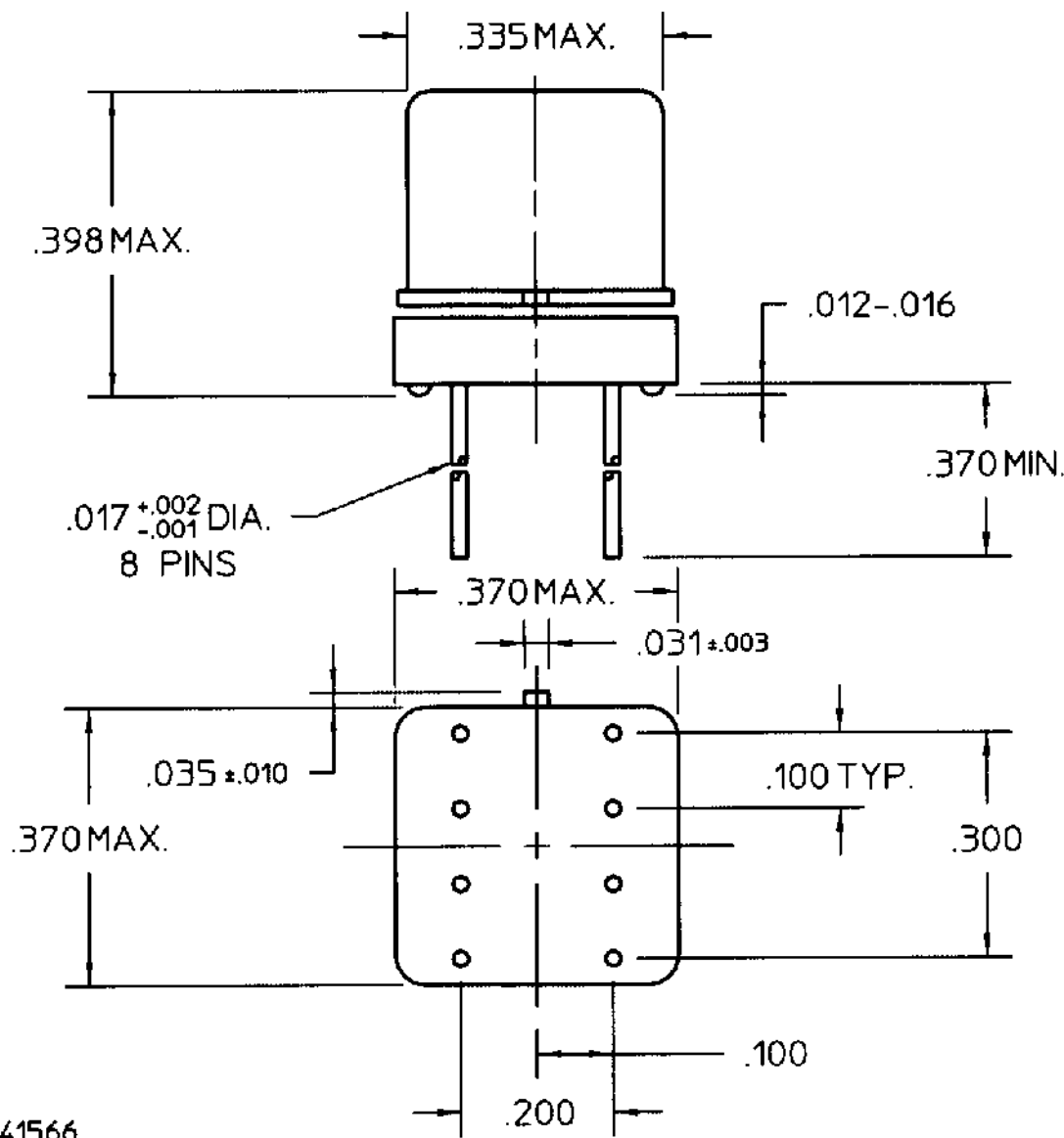

REV. 0
DCO 141566


COIL: @ 25°C
RESISTANCE 50 OHMS $\pm$ 10%
NOMINAL VOLTAGE 5.0 VDC
MUST OPERATE 2.7 VDC
MUST RELEASE 1.4 VDC MAX, 0.22 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2 MS MAX
RELEASE TIME 4 MS MAX
CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

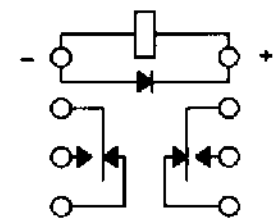

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. B.D. 12/6/99 CK 12/6/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. GPL
CUST. NO. M39016/15-106M REV.

JMACD RELAY

JMACD-5XMS