




TE Internal #: 2339800-2

Board-to-Board / Wire-to-Board, Shielded, Horizontal, 12 Position,
Board Mount, B Code, 1.8 mm [.07 in] Centerline, Signal, Data

Connectivity Headers

[View on TE.com >](#)

Automotive Parts > Automotive Connectors > Data Connectivity Headers

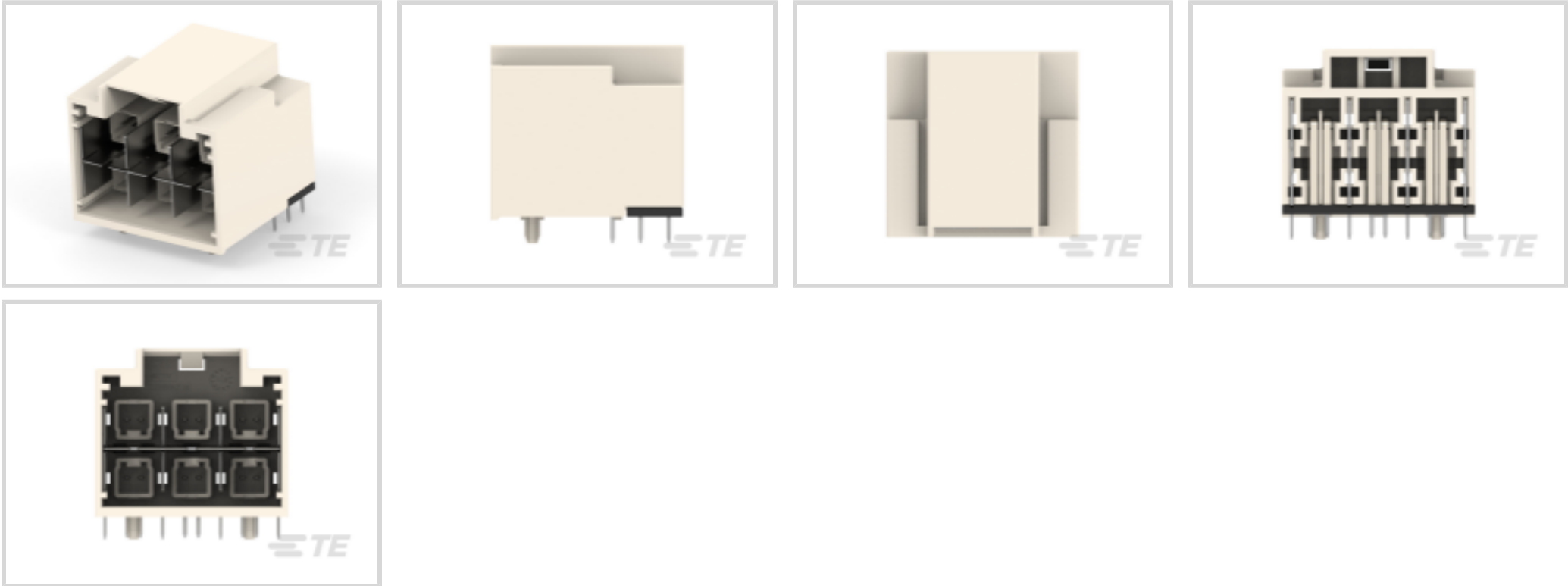

Connector System: **Board-to-Board, Wire-to-Board**

Sealable: **No**

Shielded: **Yes**

PCB Mount Orientation: **Horizontal**

Number of Positions: **12**

Features

Product Type Features

Connector & Contact Terminates To	Printed Circuit Board
Connector System	Board-to-Board, Wire-to-Board
Sealable	No

Configuration Features

Number of Rows	2
PCB Mount Orientation	Horizontal
Number of Positions	12

Body Features

Connector & Keying Code	B
-------------------------	---

Contact Features

Contact Mating Area Plating Material	Tin (Sn)
Mating Tab Width	.5 mm[.02 in]
Mating Tab Thickness	.4 mm[.01 in]
Contact Current Rating (Max)	3 A



Termination Features

Termination Method to PCB	Through Hole - Solder
---------------------------	-----------------------

Mechanical Attachment

Connector Mounting Type	Board Mount
-------------------------	-------------

Housing Features

Housing Color	White
Centerline (Pitch)	1.8 mm[.07 in]

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]

Operation/Application

Shielded	Yes
Circuit Application	Signal

Industry Standards

UL Flammability Rating	UL 94HB
------------------------	---------

Compatible Parts



TE Part # 2333538-2
2x3 PORT,MATENET,FRAME ASSY,
COD B



TE Part # 2334013-2
2X3 PORT,MATENET,FRAME housing,
COD B

Customers Also Bought




TE Part #1-2236905-1
NANO TAB 0.5X0.4,TERMINAL



TE Part #2302451-1
MATENET, MALE INSERT MODUL



TE Part #2302452-1
MATENET, FIXATION ELEMENT

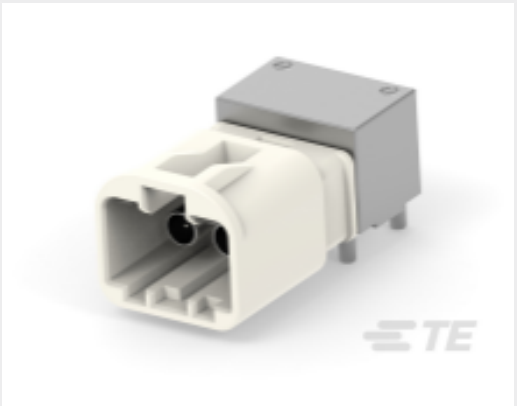

TE Part #2306368-2
2P,MATE-AX,HDR ASSY,90DEG,COD
B



Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2339800-2_A1.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_2339800-2_A1.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2339800-2_A1.3d_igs.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English