



Application Tooling > Hand Crimping Tools



Tool Grade: **Commercial Crimp Tooling**
Ratchet Configuration: **Operator Releasable & Adjustable**
Die Sets Type: **Removable/Interchangeable**
Specification Type: **TE Product Specification (114-)**
TE Certification: **Upon Request for Fee**

Features

Other

Crimp Form-Wire Barrel Type	Open Barrel - F Crimp
Tool Grade	Commercial Crimp Tooling
Ratchet Configuration	Operator Releasable & Adjustable
Die Sets Type	Removable/Interchangeable
Specification Type	TE Product Specification (114-)
TE Certification	Upon Request for Fee
Power Technology Type	Battery, Electric, Manual
Tooling Type	PRO-CRIMPER Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC



Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

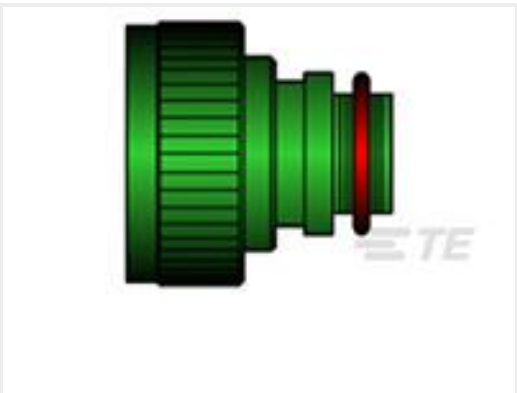
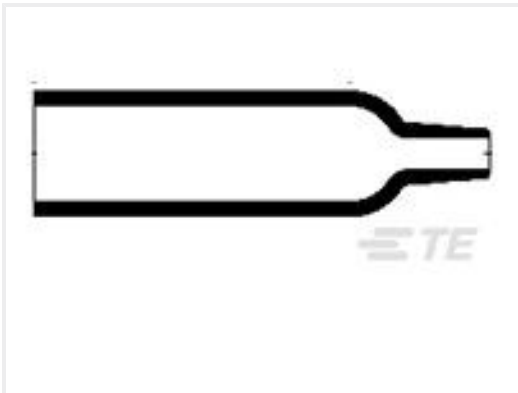
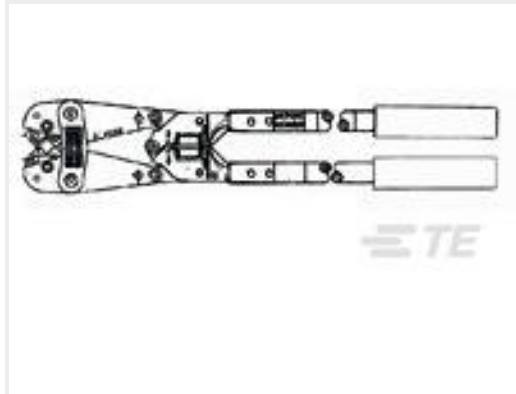
Compatible Parts

 TE Part # 321521 BUDG R 22-16COMM 22-18MIL 3/8	 TE Part # 51873-2 TERMINAL, BUDG R 22 6	 TE Part # 35212 BUDGET HOOK 16-14 6	 TE Part # 320818 BUDGET RECT 16-14 10
 TE Part # 35116 TERMINAL,BUDG SPD 16-14 8	 TE Part # 33437 BUDGET HOOK 16-14 10	 TE Part # 51873-4 TERMINAL, BUDG R 18 6	 TE Part # 331269 BUDGET RECT 12-10 8
 TE Part # 320762 BUDGET RING 12-10 3/4	 TE Part # 32186 TERMINAL,BUDG R 16-14 6	 TE Part # 34404 TERMINAL,BUDG R 12-10 8	 TE Part # 34892 TERMINAL,BUDG R 12-10 6



 TE Part # 31264 BUDG R 22-16 COMM 22-18 MIL 6	 TE Part # 32494 BUDG SPDFLG 22-16COM 22-18MIL8	 TE Part # 32503 TERMINAL,BUDG HK 16-14 8	 TE Part # 327905-1 BUDG,12-10,1/4 HOOK (TAPE)
 TE Part # 36189 BUDG R 22-16 COMM 22-18 MIL 4	 TE Part # 30972 TERMINAL,BUDG R 12-10 3/8	 TE Part # 31112 BUDGET RING 12-10 6	 TE Part # 31113 TERMINAL,BUDG R 12-10 8

Customers Also Bought

 TE Part #497361-000 TXR40AB00-1208AI	 TE Part #CJ4388-000 203W301-25-G03-0	 TE Part #36921 TERMINAL,SOLIS R 2/0 1/4	 TE Part #63721-1 RING 24-20 AWG TPBR
 TE Part #223988-1 UNV PWR MDL, GUIDE PIN PLTD	 TE Part #321868 TERMINAL SOLIS RING 1/0 3/8	 TE Part #350738-4 15P UMNL PIN HDR ASSY 94VO LF	 TE Part #600850 ROTO-CRIMP TOOL (ASI)
 TE Part #1658544-2 PIN CONT DUPL PLT STRIP HD-20	 TE Part #2-2213764-7 AV19 SPL 3A FIX RING LED RED 24V		

Documents



Datasheets & Catalog Pages

1-1773865-2_1015_Commercial Manual Hand Tools

English

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English