



Application Tooling > Hand Crimping Tools



Tool Grade: **Premium Crimp Tooling**
Ratchet Configuration: **Not Releasable, Not Adjustable**
Die Sets Type: **Fixed In Tool**
Specification Type: **MIL Spec, TE Product Specification (114-), UL/CSA**
TE Certification: **Yes – Certificate Included**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	MIL Spec, TE Product Specification (114-), UL/CSA
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Manual
Tooling Type	Double Action Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC



Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 140896-2 TERMINAL TAB FASTON PIDG 6,35	 TE Part # 160834-5 PIDG PIGGY-B FASTON	 TE Part # 160834-2 PIDG PIGGY-B FASTON	 TE Part # 5-160481-1 187 PIDG FASTON REC
 TE Part # CAT-P592-F266 PIDG FASTON Receptacle Quick Disconnects	 TE Part # 60894-2 RECEPT,PIDG FASTON 22-18 110	 TE Part # 61048-1 RECEPT,PIDG FASTON 22-18 110	 TE Part # 61048-2 RECEPT,PIDG FASTON 22-18 110
 TE Part # 2-525446-4 SLIP GAUGE, HANDTOOL	 TE Part # 5-160483-1 187 PIDG FASTON REC	 TE Part # 165564-1 110 PIDG FASTON REC	 TE Part # 61060-2 RECEPT,PIDG FASTON 22-18 110





TE Part # 165566-4
110 PIDG FASTON REC



TE Part # 640903-2
RECEPT,PIDG FASTON 22-18 250



TE Part # 5-160583-5
250 PIDG FASTON REC



TE Part # 5-160483-5
TERM, 187 FAST REC, 032 TAB, PIDG, 22-16



TE Part # 150492
TERM, RT,STRAT,DGRP, HR, 22-16, M3.5(#6)



TE Part # 165565-2
2,8 PIDG FASTON REC




TE Part # 9-160583-6
250 PIDG FASTON REC




TE Part # 9-160481-5
187 PIDG FASTON REC

Customers Also Bought

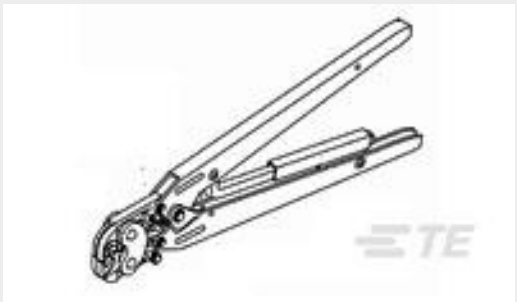


TE Part #49935
DAHT SOLIS 22-10 ASSY

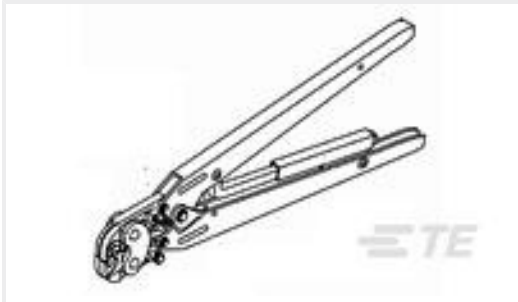

TE Part #90009-8
DAHT PIDG FASTON 16-14 ASSY




TE Part #1-320551-1
PIDG R 22-16 COMM 22-18 MIL 8

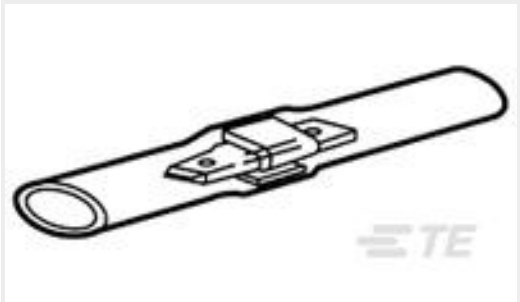


TE Part #1-321235-1
RECEPT, FASTON SPLICE 22-10



TE Part #640903-2
RECEPT,PIDG FASTON 22-18 250

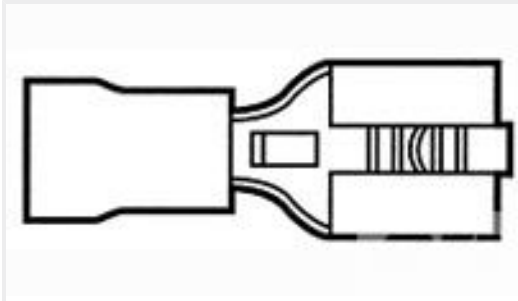

 TE Part #640905-2
RECEPT,PIDG FASTON 16-14 250



TE Part #709020-4
CT 10-70 B D9

Documents

Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (non U.S.)

English