


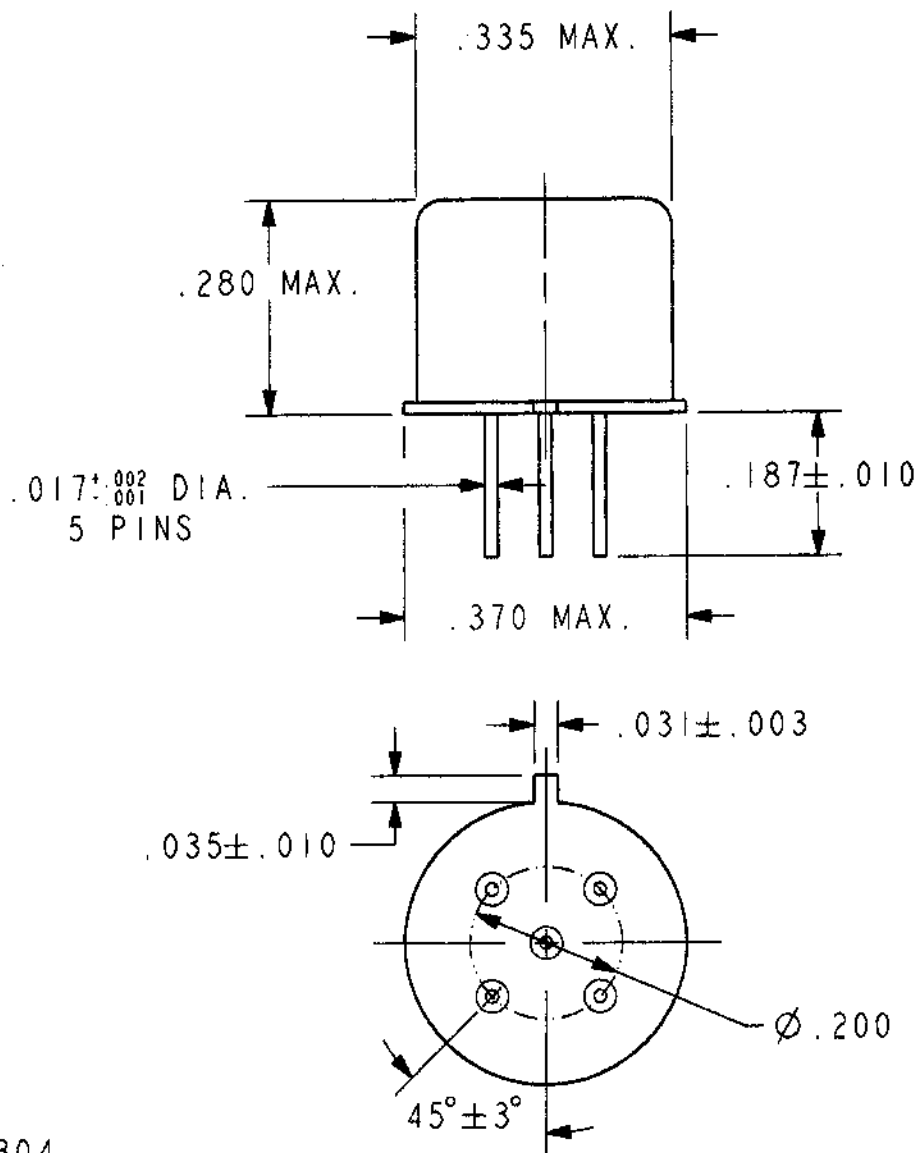


REV. 0
DCO 143304

COIL: @ 25°C
RESISTANCE 2000 OHMS ±10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.2 VDC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:
VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 4.0 MS MAX.
CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

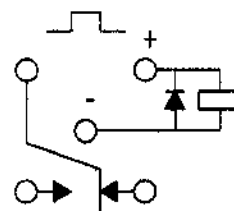

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 11/13/01

11/13/01

CII Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M39016/23-024P REV.

"JIMAD" RELAY

J1MAPD-26XP