



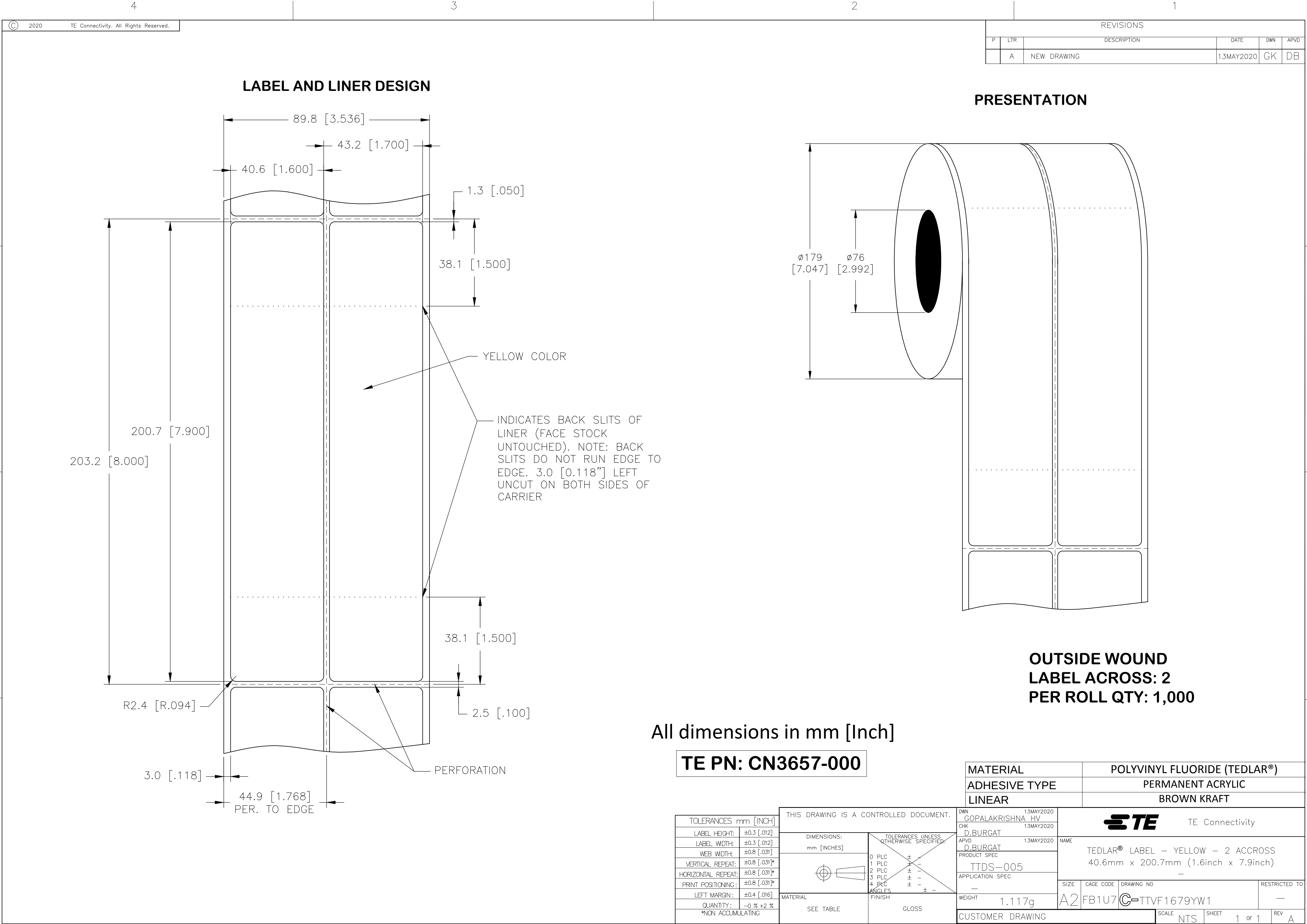

REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	13MAY2020	GK	DB

PRESENTATION

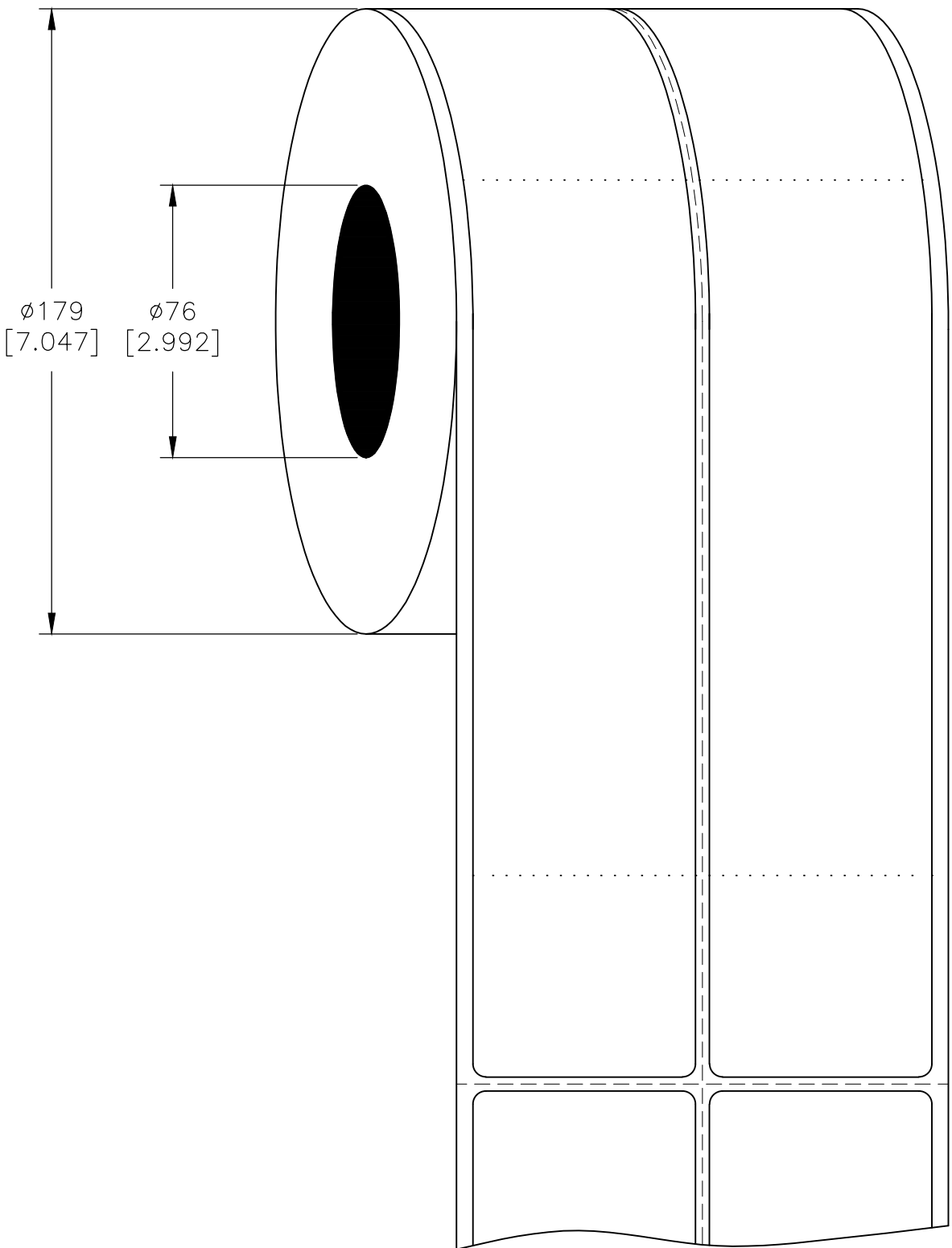

OUTSIDE WOUND
LABEL ACROSS: 2
PER ROLL QTY: 1,000

All dimensions in mm [Inch]

TE PN: CN3657-000

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC ± 1 PLC ± 2 PLC ± 3 PLC ± 4 PLC ± ANGLES ±
MATERIAL SEE TABLE	FINISH GLOSS

MATERIAL ADHESIVE TYPE LINEAR		POLYVINYL FLUORIDE (TEDLAR®) PERMANENT ACRYLIC BROWN KRAFT	
DWN GOPALAKRISHNA HV CHK D.BURGAT APVD D.BURGAT PRODUCT SPEC TTDS-005 APPLICATION SPEC —		NAME TEDLAR® LABEL – YELLOW – 2 ACCROSS 40.6mm x 200.7mm (1.6inch x 7.9inch) —	
WEIGHT 1.117g	SIZE A2	CAGE CODE FB1U7	DRAWING NO C=TTVF1679YW1
CUSTOMER DRAWING		SCALE NTS	SHEET 1 OF 1
		REV A	