


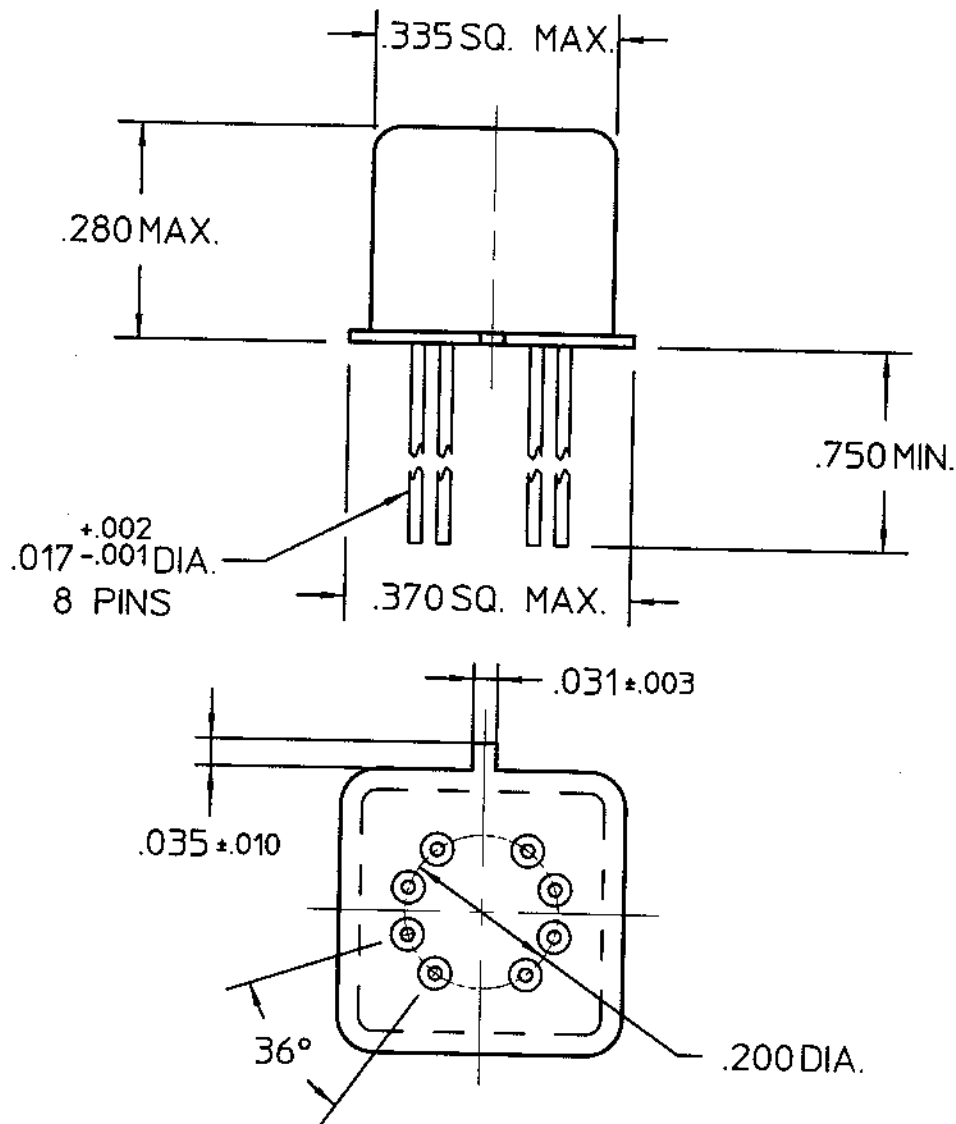


REV. 1
DCO 142816

COIL: @ 25°C
 RESISTANCE _____ 390 OHMS $\pm 20\%$
 NOMINAL VOLTAGE _____ 12.0 VDC
 MUST OPERATE _____ 8.4 VDC

 MUST RELEASE _____

ENVIRONMENT:
 VIBRATION _____ 10 _____ CPS TO _____ 500 _____ CPS @ _____ 10 _____ g's
 SHOCK _____ 30 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -55 _____ °C TO _____ +85 _____ °C
 NOTES: _____ OPERATE TIME 4 MS MAX
 _____ RELEASE TIME 3 MS MAX

CUSTOMER DATA SHEET

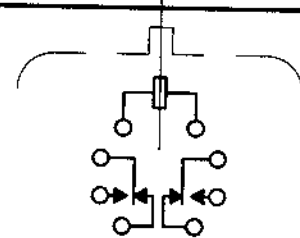

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 2/14/01

CK. 3/A/01/003

CII Technologies
 advanced control electronic solutions

CUST. _____ C. I. I. STD.

CUST. NO. _____ REV. _____

MW6 RELAY
MICROWAVE

MW6-12A