


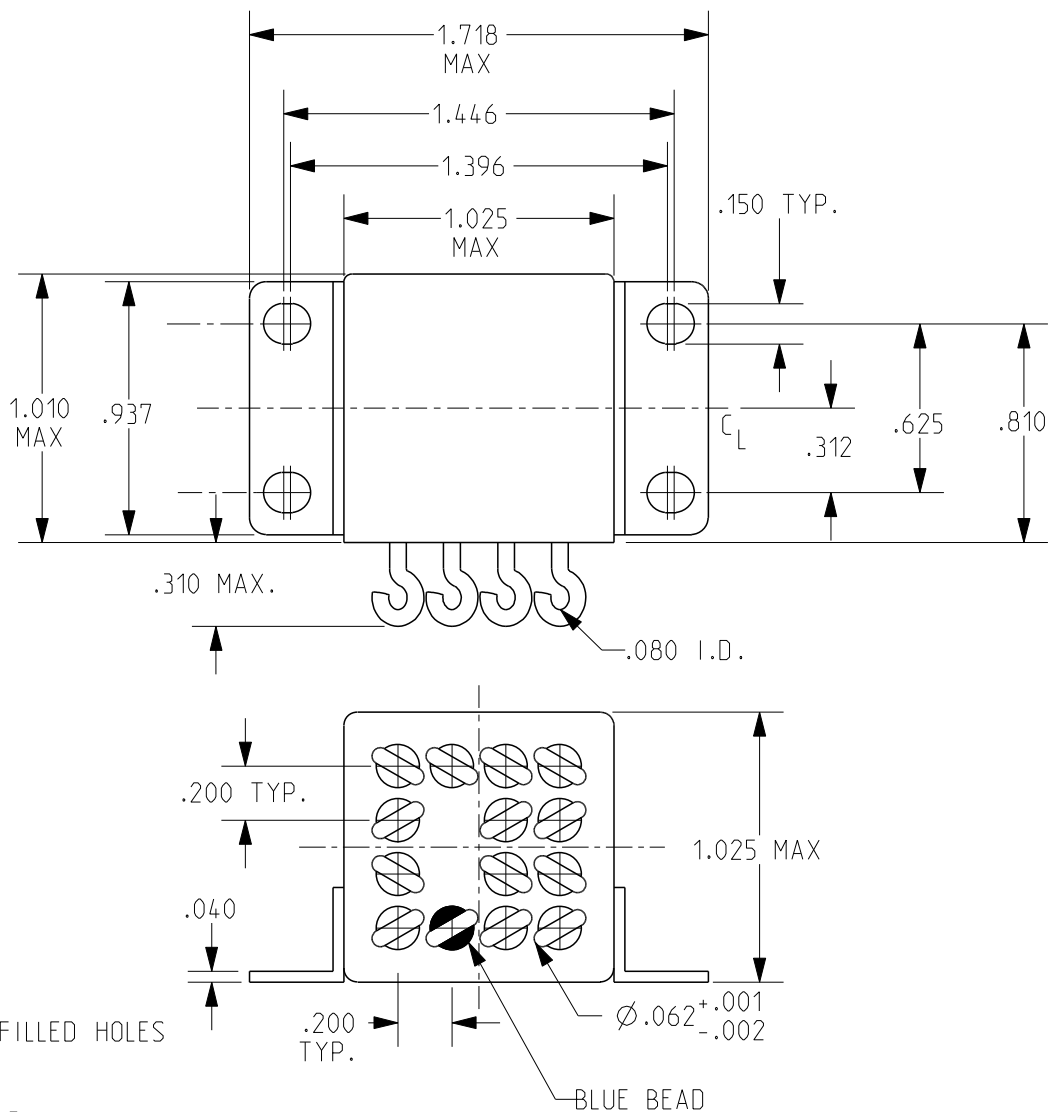

REV. C

DCO 301387


TOLERANCES $\pm .010"$ - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 290 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
 COIL TRANSIENT SUPPRESSION: 42 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION 57 Hz TO 3000 Hz @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.
 CONTACT STABILIZATION 2.5 MS MAX.
 CONTACT BOUNCE 1 MS MAX.
 CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

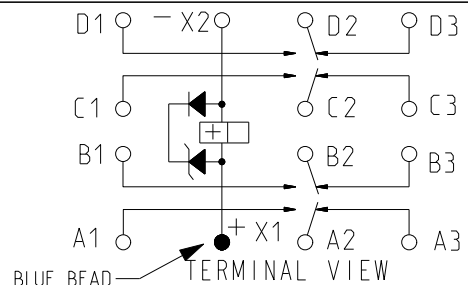

CONTACT RATING: LOW LEVEL
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
 100,000 OPERATIONS

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL
 CUST. NO. M83536/16-024M REV. ----

TE NUMBER
 2-1617754-3

CII PART NUMBER
 FCA-410-1624M