
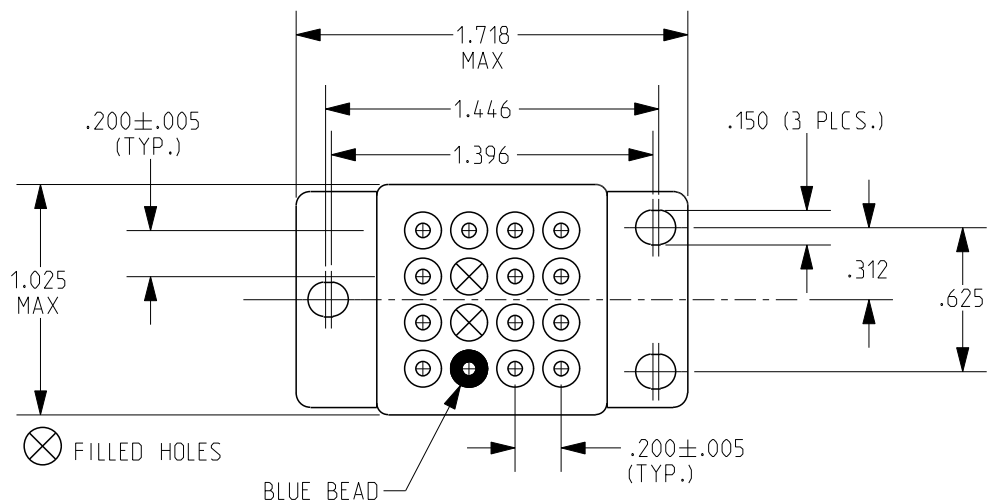


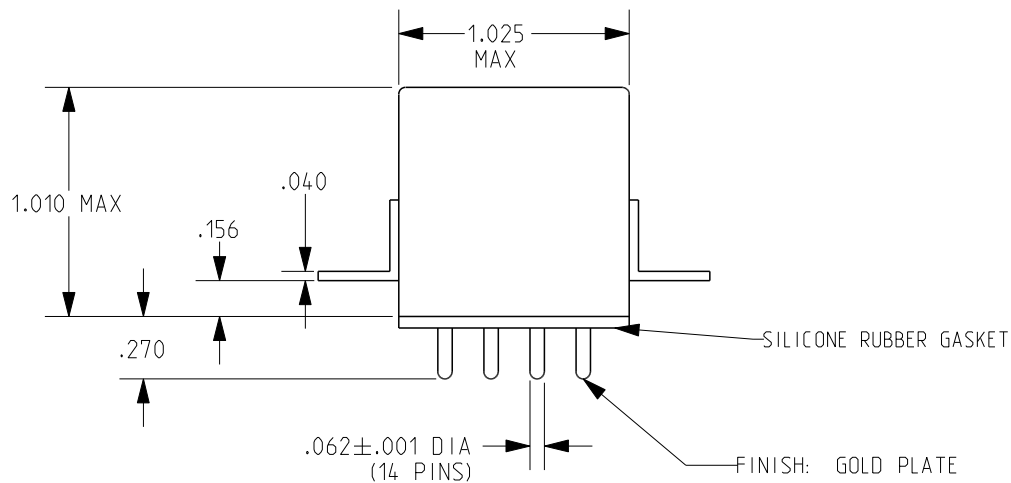

REV. C

DCO 301387

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C

RESISTANCE 290 OHMS ±10%

NOMINAL VOLTAGE 28 VDC

MUST OPERATE 13.5 VDC MAX.

COIL TRANSIENT SUPPRESSION: 42 VDC MAX.

MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 200 g's 6 MS. DURATION

TEMPERATURE -70 °C TO +125 °C


NOTES: OPERATE, RELEASE 15 MS MAX.

CONTACT STABILIZATION 2.5 MS MAX.

CONTACT BOUNCE 1 MS MAX.

CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

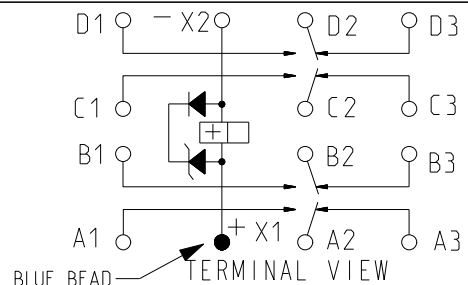

CONTACT RATING: LOW LEVEL
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
100,000 OPERATIONS

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL

CUST. NO. M83536/16-022M REV. ----

TE NUMBER
2-1617754-1

CII PART NUMBER

FC A-410-1622M