


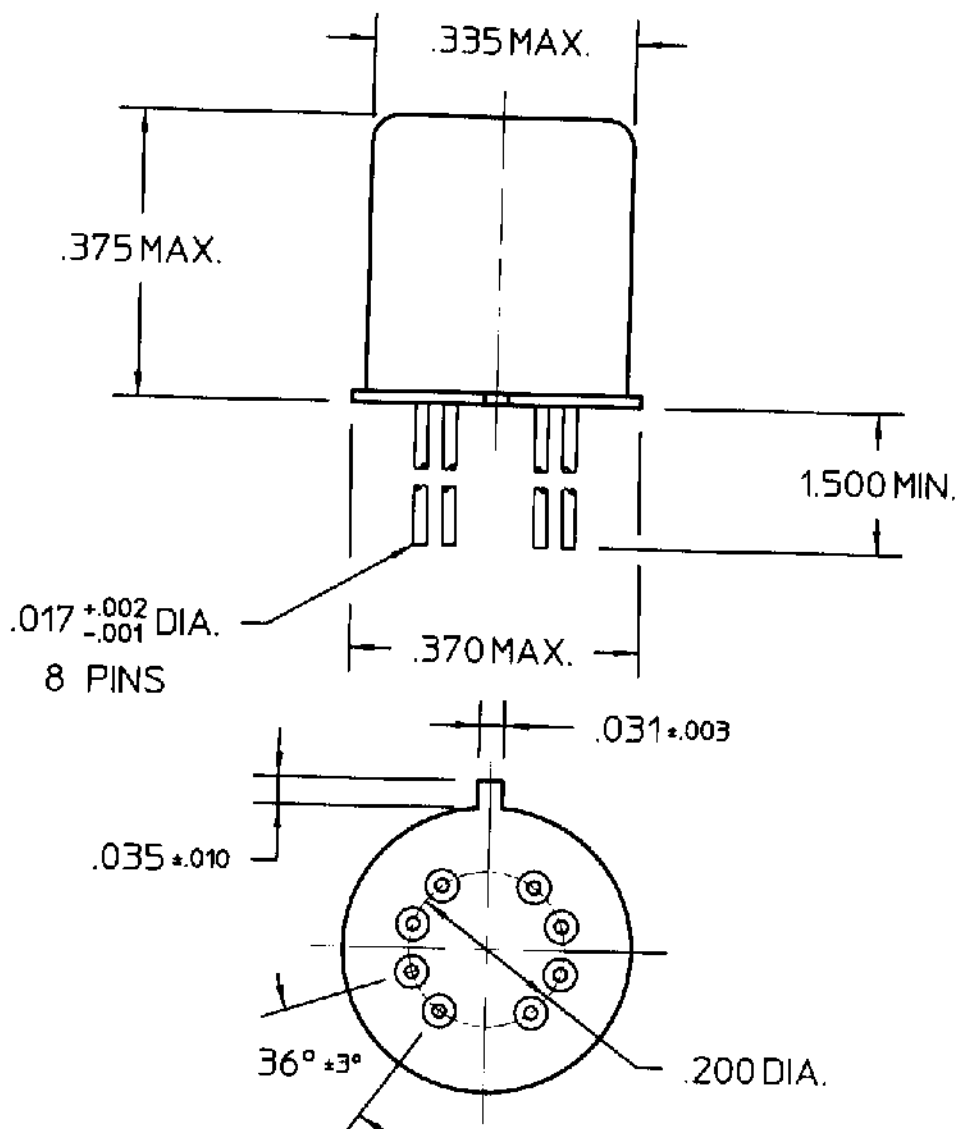

REV. 0  
DCO 141918


COIL: @ 25°C  
 RESISTANCE 125 OHMS  $\pm 10\%$   
 NOMINAL VOLTAGE 5.0 VDC  
 MUST OPERATE 2.6 VDC  
 TURN-ON BASE CURRENT .28 mADC  
 MUST RELEASE 1.4 VDC MAX, 0.22 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 3.5 MS MAX  
 TURN-OFF TIME 7.5 MS MAX  
 CONTACT STABILIZATION TIME 2.0 MS MAX

CUSTOMER DATA SHEET

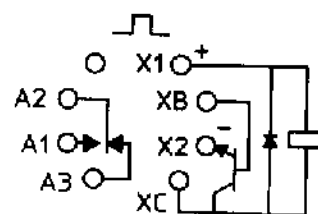

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 4-18-00

FK. *[Signature]* 9/20/00

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
 CUST. NO. M28776/4-017P REV.

RELAY

J1MSWT-5XP