


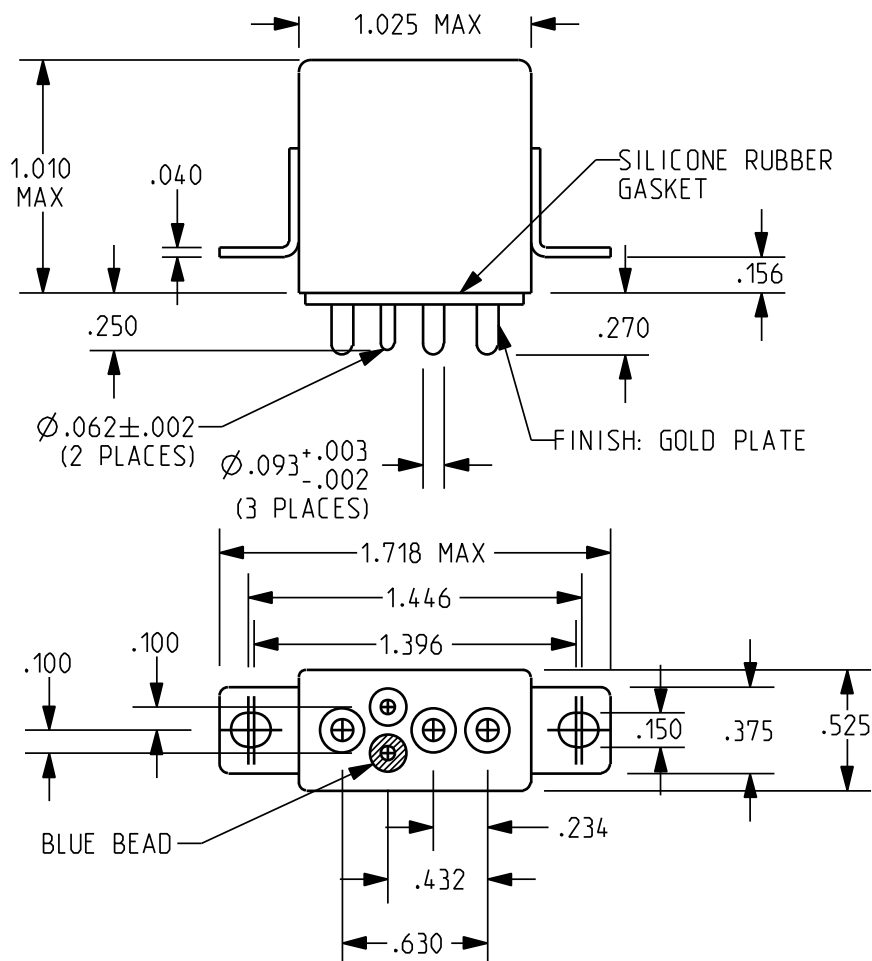

REV. A
DCO 300860

TOLERANCES $\pm .010$ " - UNLESS
OTHERWISE SPECIFIED


COIL: @ 25°C
RESISTANCE 320 OHMS $\pm 10\%$
NOMINAL VOLTAGE 28 VDC
MUST OPERATE 13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.
MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 200 g's 6 MS. DURATION
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.
CONTACT BOUNCE 1 MS MAX.
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

A1 - X2 A2 A3

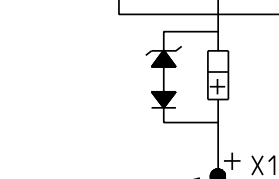

BLUE BEAD
TERMINAL VIEW

CONTACT RATING:
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

Tyco Electronics

©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL
CUST. NO. M83536/37-003L REV. ----

TE NUMBER
5-1617791-2

CII PART NUMBER
FCA-125-3703L