


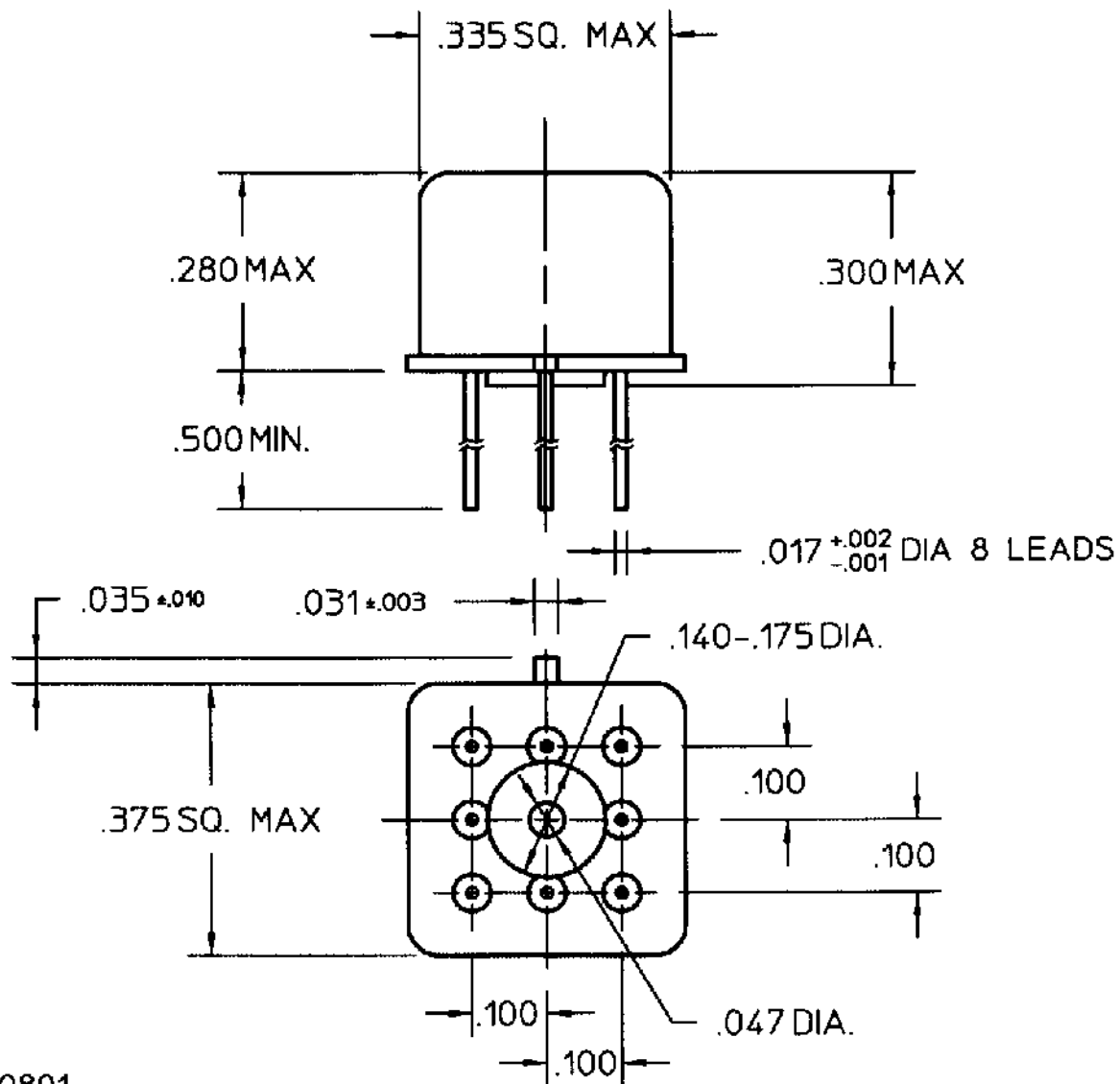

REV. 0
DCO 140801


COIL: @ 25°C
RESISTANCE 390 OHMS $\pm$ 10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.0 VDC
MUST RELEASE 4.0 VDC MAX. 0.63 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX
RELEASE TIME 4.0 MS MAX
CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

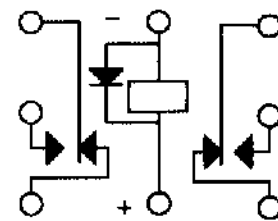

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/11/98 CK. 12/11/98

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. QPL
CUST. NO. M39016/18-040M

TYPE JMGAD RELAY

JMGACD-12MW