


ACCELERATE[®] HP

HIGH-PERFORMANCE ARRAY SYSTEM

(0.635 mm) .025" PITCH

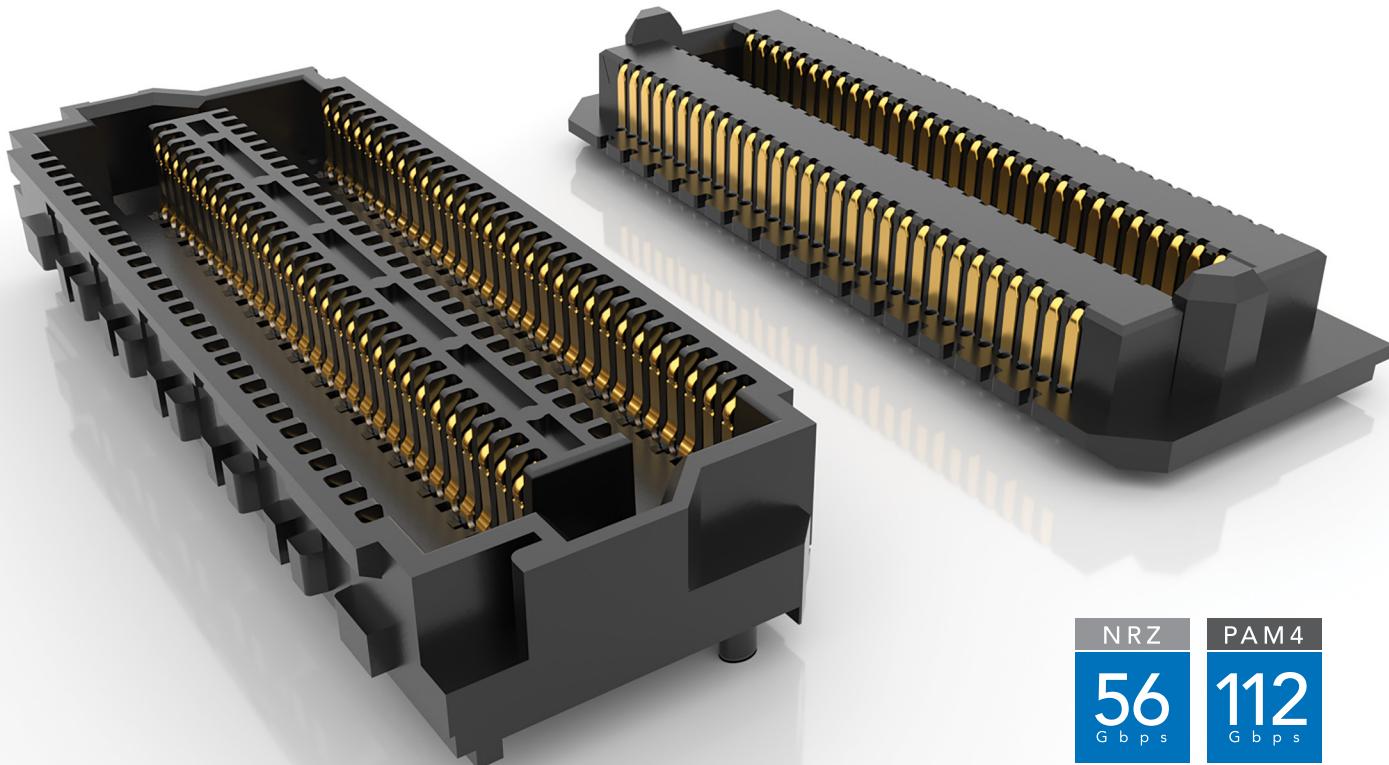


NRZ	PAM4
56 Gbps	112 Gbps

FEATURES & BENEFITS

- Flexible open-pin-field and extreme performance solution
- Low profile 5 mm and up to 10 mm stack heights
- 0.635 mm pitch
- Up to 800 total pins; roadmap to 1,000+ pins
- Data rate compatible with PCIe® 6.0/CXL® 3.2 and 100 GbE
- Analog over Array™ capable
- Road Map: 6 and 10 rows, additional position counts



Right-angle connector
(samtec.com/APF6-RA)

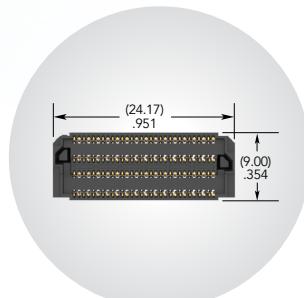

APF6 Series; 120 pins

KEY SPECIFICATIONS (APM6/APF6)


TOTAL PINS	INSULATOR MATERIAL	CONTACT MATERIAL	PLATING	OPERATING TEMP RANGE	CURRENT RATING	VOLTAGE RATING	LEAD-FREE SOLDERABLE
40 - 800	Black LCP	Copper Alloy	Au or Sn over 50 μ " (1.27 μ m) Ni	-55 °C to +125 °C	1.2 A (4 pins powered)	150 VAC/212 VDC	Yes

PCI-SIG®, PCI Express® and the PCIe® design marks are registered trademarks and/or service marks of PCI-SIG.


(0.635 mm) .025" PITCH • 112 Gbps PAM4 OPEN-PIN-FIELD ARRAYS

SERIES	NO. OF POSITIONS	LEAD STYLE	PLATING OPTION	NO. OF ROWS	0	OPTION	"X"R
APM6 Terminal	-020, -040, -060, -100 (per row)	-01.5 = 1.5 mm (APM6 only)	-L = 10 μ " (0.25 μ m) Gold on contact area, Matte Tin on tail	-04 = Four Rows		(Leave blank for no alignment pin)	-TR = Tape & Reel
APF6 Socket		-01.9 = 1.9 mm (APM6 only) (Only mates with an APF6-RA)		-08 = Eight Rows (Lead Style -01.5 & -03.5 with 100 Positions only)		-A = Alignment Pin	-FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

APM6
Board Mates:
APF6, APF6-RA

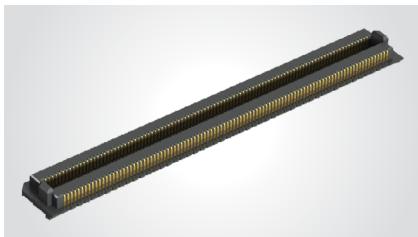

Standoffs:
GPSO

 

NO. OF POSITIONS PER ROW	A	LEAD STYLE	B	NO. OF ROWS	C
-020	(17.82).701	-01.5	(3.33).131	-04	(8.75).344
-040	(30.52) 1.201	-01.9	(3.71).146	-08	(17.95).707
-060	(43.22) 1.701				
-100	(68.62) 2.701	-06.5	(8.33).328		

ALSO AVAILABLE
Contact Samtec

Other platings


View complete specifications at: samtec.com?APM6

MATED HEIGHTS *


APF6 LEAD STYLE	APM6 LEAD STYLE	
	-01.5	-06.5
-03.5	(5.00 mm).197"	(10.00 mm).394"

* Processing conditions will affect mated height.

APF6
Board Mates:
APM6

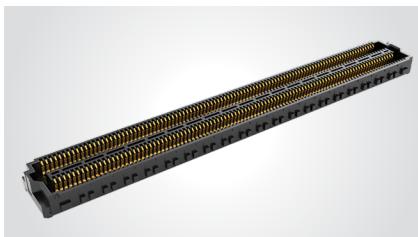

Standoffs:
GPSO

 

OTHER SOLUTIONS

Right-angle

samtec.com?APF6-RA

Notes:

Some sizes, styles and
options are non-standard,
non-returnable

View complete specifications at: samtec.com?APF6

NO. OF POSITIONS PER ROW	A	NO. OF ROWS	B
-020	(17.82).701	-04	(9.00).354
-040	(30.52) 1.201	-08	(18.20).717
-060	(43.22) 1.701		
-100	(68.62) 2.701		