

50 Ω BNC TO 4 GHz

BNC Cable Assemblies

RF174, RF178, RF316,
RS316



SERIES	END 1 CONNECTOR	END 2 CONNECTOR	OVERALL LENGTH
RF174 = RG 174 Cable			
RF178 = RG 178 Cable			
RF316 = RG 316 Cable, Single Braid Shield			
RS316 = RG 316 Cable, Double Shielded	-04SP3 = BNC Straight Plug (RS316 not available)	-04BJ2 = BNC Bulkhead Jack	—"XXXX" = Overall Length in millimeters -0100 (100 mm) 3.94" minimum

ALSO AVAILABLE

50 Ω: MCX, MMCX, SMA, SMB, TNC,
N Type = RF174, RF178, RF316

50 Ω: MCX, MMCX, SMA, TNC = RS316

BNC Cable Connectors

BNC5-CA



Supplied with pins, washers,
nuts, gaskets and ferrules.
See website for dimensions.

CONNECTORS FOR INDUSTRY STANDARD CABLES	
*BNC5-P-C-GN-ST-CA1	RG 174/316 Cable
*BNC5-P-C-GN-ST-CA2	RG 178 Cable
*BNC5-J-C-GN-ST-BH1	RG 174/316 Cable, Bulkhead
BNC5-J-C-GN-ST-BH2	RG 178 Cable, Bulkhead
BNC5-J-C-GN-ST-BH1S	RG 316 Double Shielded Cable, Bulkhead


*Add "-B" to the end of the part number for bulk packaging

P-C = Cable Plug

J-C = Cable Jack

GN = Plating (10 μ " Gold on contact, Nickel on body)

ST = Straight

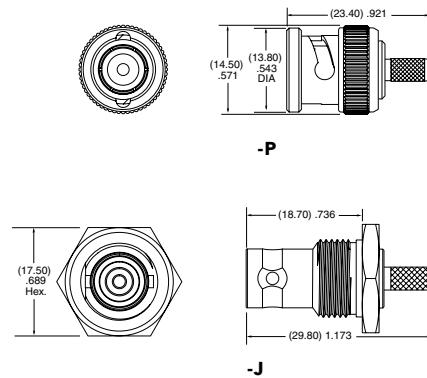

-P

-J