



JSOM-1524-02

JSOM-1524-02

## JSOM SERIES

# MICRO JACK SCREW STANDOFF

## SPECIFICATIONS

For complete specifications and recommended PCB layouts see [www.samtec.com?JSOM](http://www.samtec.com?JSOM)

**Material:**  
Stainless Steel

**ALSO AVAILABLE**  
Contact Samtec

Other heights

Works with  
PCI/104-Express™  
systems

| INDUSTRY STANDARD | INTERCONNECTS |               |       |              |
|-------------------|---------------|---------------|-------|--------------|
|                   | TERMINAL      | SOCKET        | BANKS | STACK HEIGHT |
| PCI/104-Express™  | ASP-129637-03 | ASP-129646-03 | 3     | 15.24 mm     |
| PCI/104-Express™  | ASP-129637-13 | ASP-129646-22 | 1     | 15.24 mm     |
| SUMIT™            | ASP-129637-01 | ASP-129646-01 | 1     | 15.24 mm     |

JSOM




BOARD  
STACKER

LEAD STYLE

**-1524**= (15.24 mm) .600"  
Stack Height**-02**

= Female Thread

## APPLICATION

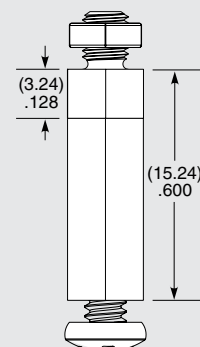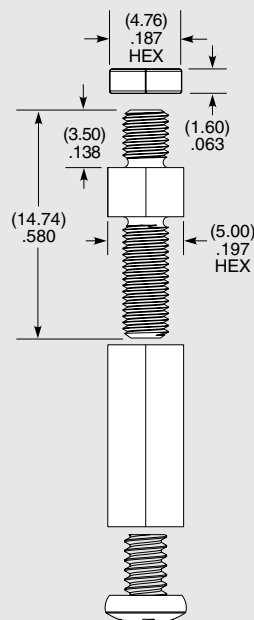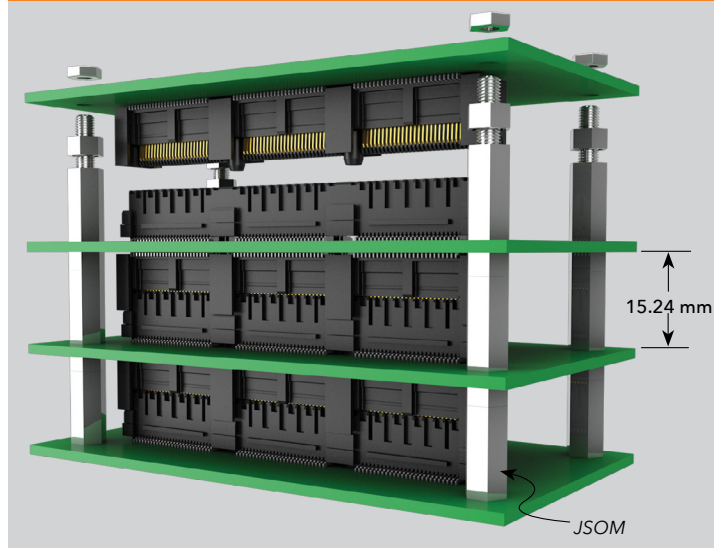

Components are to be packaged in separate bags unassembled.